

 
960H Color or Standard BW Angle Mount Camera

CVC695AM 3.6mm wide angle lens, horizontal 72° / vertical 53°, color


CVC95AM 3.6mm wide angle lens, horizontal 72° / vertical 53°, BW

Features

- Weather/tamper resistant cover
- Features a 3.6mm wide angle lens that views at a downward angle of 38°
- Includes tamper resistant screw for vandal resistant mounting
- 700 TV lines of resolution
- 5 year warranty



2.5" (L)

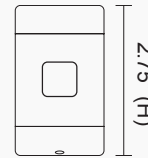

2.75" (H)

2.25" (W)



Specifications

	CVC695AM	CVC95AM
Image Sensor	1/3" Sony Super HAD II™ color CCD	1/3" BW CCD
Resolution.....	700 TV lines	420 TV lines
Minimum Illumination.....	0.001 lux (sense-up)	0.02 lux
Effective Pixels	976 (H) x 494 (V)	512 (H) x 492 (V)
Electronic Shutter Speed.....	Auto: 1/60 sec. – 1/100,000 sec.	Auto: 1/60 sec. – 1/100,000 sec.
Video Output.....	1.0Vp-p / 75 ohms	1.0Vp-p / 75 ohms
S/N Ratio	More than 52dB	More than 50dB
Scanning Frequency.....	15.75kHz (H) / 60Hz (V)	15.75kHz (H) / 60Hz (V)
Output.....	Video - BNC, Power - DC jack	Video - BNC, Power - DC jack
Operating Temperature/ Humidity.....	14° F – 122° F / within 95% RH	14° F – 122° F / within 95% RH
Power Consumption	210mA	150mA
Power Supply	12VDC (UL and CSA listed power supply included)	12VDC (UL and CSA listed power supply included)
Housing	18 gauge stainless steel	18 gauge stainless steel
Dimensions.....	2.25" (W) x 2.75" (H) x 2.5" (L)	2.25" (W) x 2.75" (H) x 2.5" (L)
Weight	6.8 oz.	6.8 oz.

Optional Lenses

CVC95AM2.5.....2.5mm lens	CVC695AM2.5...2.5mm lens
CVC95AM6.....6mm lens	CVC695AM2.9...2.9mm lens
CVC95AM8.....8mm lens	CVC695AM6.....6mm lens
CVC95AM12.....12mm lens	CVC695AM8.....8mm lens
	CVC695AM12....12mm lens