


960H Ultra Wide Angle Color Bullet Camera

CVC638170 2.2mm lens, 170° angle of view, black housing

Features

- 170° field of view allows you to see small areas like elevators, vestibules, and counting rooms without any loss of coverage.
- The ultra-wide angle lens will fully view these small spaces when properly installed and positioned
- 1/3" Sony Super HAD II™ color CCD
- 700 TV lines of resolution
- Miniature mounting bracket included
- IP67 compliant, weather resistant
- 5 year warranty

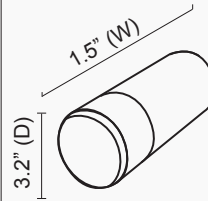

Specifications

Image Sensor	1/3" Sony Super HAD II™ color CCD
Resolution.....	700 TV lines
Minimum Illumination.....	0.001 lux (sense-up on)
Effective Pixels	976 (H) x 494 (V)
Total Pixels	1020 (H) x 508 (V)
Electronic Shutter	Auto 1/60 sec. – 100,000 sec.
Scanning Frequency.....	15.75kHz (H) / 60Hz (V)
Scanning System.....	2:1 interlace
S/N Ratio	More than 52dB
Video Output.....	1.0Vp-p / 75 ohms
Power Consumption	115mA
Power Supply	12VDC (UL & CSA listed power supply included)
Operating Temperature/	
Humidity.....	14° F – 122° F / within 95% RH
Dimensions.....	1.5" (W) x 3.2" (Dia.)
Weight	6.53 oz.