
64151

OSRAM ORIGINAL LINE | Halogen headlight lamps for cars



Areas of application

- Headlight

Product benefits

- OEM Quality
- Wide product range
- Reliable quality

Product features

- Original spare parts

Product datasheet

Technical data

Electrical data


Power input	68 W ¹⁾
Nominal wattage	55.00 W
Nominal voltage	12 V
Test voltage	13.2 V

¹⁾ Maximum

Photometrical data

Color temperature	3200 K
Luminous flux	1450 lm
Luminous flux tolerance	±15 %

Dimensions & weight

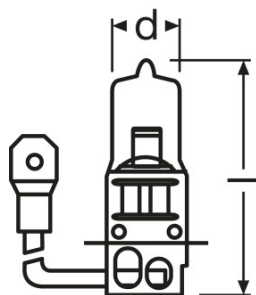

Length	42.0 mm
Diameter	11.5 mm
Product weight	6.55 g

Lifespan

Lifespan B3	400 h
Lifespan Tc	650 h

Additional product data

Base (standard designation)	PK22s
-----------------------------	-------

Certificates & standards

ECE category	H3
--------------	----

Country specific categorizations

Product datasheet

Order reference	64151 55W 12V P
------------------------	-----------------

Country specific information

Product code	METEL code	SEG number	STK number	UK Org
4050300001494	OSRA64151	8328030	4739915	-
4050300925349	OSRA64151BL1	8328390	4730318	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300001494	64151	Folding carton box 1	25 mm x 23 mm x 70 mm	0.04 dm ³	7.00 g
4050300211176	64151	Bundle 10	104 mm x 50 mm x 82 mm	0.43 dm ³	84.60 g
4050300211183	64151	Shipping carton box 100	122 mm x 109 mm x 361 mm	4.80 dm ³	941.00 g
4050300925349	64151	Blister 1	76 mm x 17 mm x 108 mm	0.14 dm ³	18.00 g
4008321142306	64151	Shipping carton box 10	125 mm x 145 mm x 225 mm	4.08 dm ³	245.17 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.