

HALOLINE ECO SST 160 W 230 V R7S

HALOLINE ECO SUPERSTAR | Double ended halogen lamps with tube base



Areas of application

- Entrance lighting
- Pathway lighting
- Garden lighting
- Traffic areas
- Shops
- Restaurants, hotels and similar prestigious applications
- Offices, public buildings
- Ideal for emphasizing and accentuating the structure of a room

Product benefits

- Brilliant ECO accent lighting
- Direct replacement for standard tubular halogen lamps
- Significantly lower CO₂ emissions
- Lower thermal output (compared with the standard reference product)
- No transformer required

Product features

- Average life: 2,000 h
- Dimmable
- Color rendering index R_a : 100
- Base: R7s



Product datasheet

Technical data

Electrical data

Nominal wattage	160 W
Nominal voltage	230 V
Rated wattage	160 W
Claimed equiv. conventional lamp power	200 W
Power factor λ	1.00
Energy consumption	160 kWh/1000h

Light technical data

Nominal luminous flux	3100 lm
Color temperature	2900 K
Light color as per EN 12464-1	Warm White
Rated luminous flux	3100 lm
Color rendering index Ra	100
Starting time	0.0 s
Warm-up time (60 %)	0.00 s
Lumen main.fact.at end of nom.life time	0.80

Dimensions & weight



Product line drawing

Diameter	12.0 mm
Overall length	114.2 mm
Length	114.2 mm
Outer bulb	T12

Product datasheet

Colors & materials


Lamp mercury content	0.0 mg
Mercury-free	Yes

Lifespan

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000 ¹⁾

¹⁾ At 1 min on / 3 min off

Additional product data

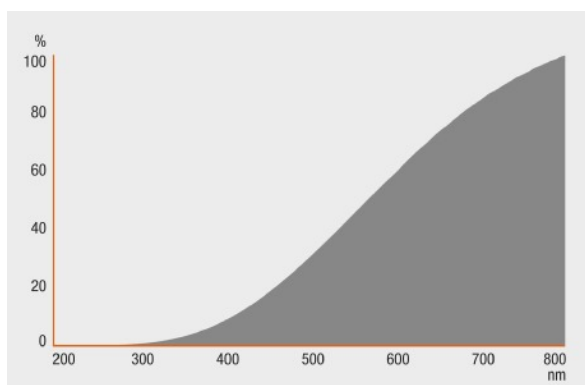

Spectral power distribution

Base (standard designation)	R7s
New article	NEW
Footnote used only for product	Fuse protection with indicated values recommended acc. to IEC60357, EN60357/For outdoor applications and operation in damp locations special approved fixtures are required/Technical and light values are subject to be changed

Capabilities

Fuse, quick-acting	2.0 A
Burning position	Any

Product datasheet

Dimmable	Yes
-----------------	-----

Certificates & standards

Energy efficiency class	C
--------------------------------	---

Country specific categorizations

ILCOS	HDG-160-230-R7s-114,2
Order reference	64698 ECO SST

Country specific information

Product code	METEL-Code	SEG number	STK-Number	UK Org
4008321977731	-	8327719	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321977731	HALOLINE ECO SST 160 W 230 V R7S	Blister 1	120 mm x 16 mm x 140 mm	0.27 dm ³	19.60 g
4008321977748	HALOLINE ECO SST 160 W 230 V R7S	Shipping carton box 10	145 mm x 124 mm x 149 mm	2.68 dm ³	277.40 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.