

HALOLINE 1000 W 230 V R7S

HALOLINE Standard | Double ended halogen lamps with tube base



Areas of application

- Ideal for emphasizing and accentuating buildings
- General illumination
- Entrance lighting
- Pathway lighting
- Garden lighting
- Traffic areas
- Shops
- Restaurants, hotels and similar prestigious applications

Product benefits

- Brilliant accent light
- No transformer required
- Contains no mercury

Product features

- Average life: 2,000 h
- 100 % dimmable
- Color rendering index R_a : 100
- Color temperature: 3,000 K
- Burning position: p15

Product datasheet

Technical data

Electrical data

Nominal wattage	1000 W
Nominal voltage	230 V
Rated wattage	1000 W
Claimed equiv. conventional lamp power	1000 W
Power factor λ	1.00
Energy consumption	1000 kWh/1000h

Light technical data

Nominal luminous flux	22000 lm
Color temperature	2900 K
Light color as per EN 12464-1	Warm White
Rated luminous flux	22000 lm
Color rendering index Ra	100
Starting time	0.0 s
Warm-up time (60 %)	0.00 s
Lumen main.fact.at end of nom.life time	0.80

Dimensions & weight



Product line drawing

Diameter	12.0 mm
Overall length	185.7 mm
Length	191.1 mm
Outer bulb	T12

Product datasheet

Colors & materials


Lamp mercury content	0.0 mg
Mercury-free	Yes

Lifespan

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000 ¹⁾

¹⁾ At 1 min on / 3 min off

Additional product data

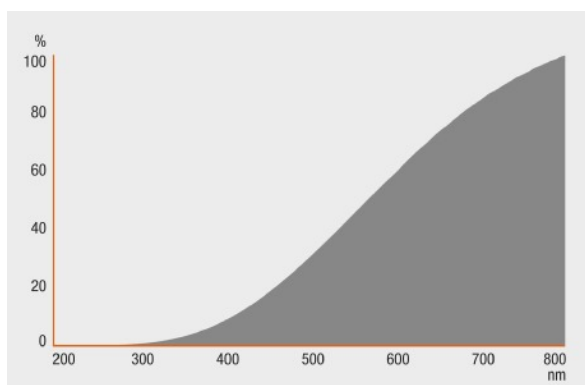

Spectral power distribution

Base (standard designation)	R7s
Footnote used only for product	Fuse protection with indicated values recommended acc. to IEC60357, EN60357/For outdoor applications and operation in damp locations special approved fixtures are required

Capabilities

Burning position	p15
Fuse, quick-acting	6.3 A
Dimmable	Yes

Product datasheet

Non-standard conditions	P 15
--------------------------------	------

Certificates & standards

Energy efficiency class	C
--------------------------------	---

Country specific categorizations

ILCOS	HDG-1000-230-R7s-191,1
Order reference	64740

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.