

64150ULT

ULTRA LIFE | Halogen headlight lamps for cars



Areas of application

- Headlight
- Ideal for use in clear-glass headlights

Product benefits

- An ideal daytime running lamp due to long life span
- Up to triple the lifetime (compared to standard halogen lamps)
- 3 year guarantee (on halogen headlight lamps)

Product features

- Modern design with a silver cap (H4/H7)

Technical data

Electrical data


Power input	68 W ¹⁾
Nominal wattage	55 W
Nominal voltage	12 V
Test voltage	13.2 V

¹⁾ Maximum

Light technical data

Color temperature	3200 K
Luminous flux tolerance	±15 %

Dimensions & weight

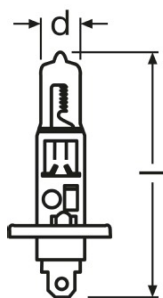

Product line drawing

Length	67.5 mm
Diameter	9.0 mm
Product weight	6.91 g

Lifespan

Lifespan B3	1200 h
Lifespan Tc	2000 h

Additional product data

Base (standard designation)	P14.5s
-----------------------------	--------

Certificates & standards

Product datasheet

ECE category	H1
---------------------	----

Country specific categorizations

Order reference	64150ULT
------------------------	----------

Country specific information

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321416162	OSRA64150ULTDUO	-	-	-
4008321416209	OSRA64150ULT	-	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321416100	64150ULT	Blister 1	81 mm x 33 mm x 135 mm	0.36 dm ³	15.33 g
4008321416117	64150ULT	Shipping carton box 10	103 mm x 146 mm x 225 mm	3.38 dm ³	238.00 g
4008321416162	64150ULT	Unpacked 2	95 mm x 34 mm x 115 mm	0.37 dm ³	97.82 g
4008321416179	64150ULT	Shipping carton box 20	240 mm x 106 mm x 250 mm	6.36 dm ³	1109.00 g
4008321416209	64150ULT	Folding carton box 1	25 mm x 23 mm x 70 mm	0.04 dm ³	3.00 g
4008321416216	64150ULT	Bundle 10	116 mm x 70 mm x 50 mm	0.41 dm ³	78.67 g
4008321416223	64150ULT	Shipping carton box 100	122 mm x 109 mm x 361 mm	4.80 dm ³	996.00 g
4008321416315	64150ULT	Blister 2	77 mm x 22 mm x 116 mm	0.20 dm ³	30.82 g
4008321416322	64150ULT	Shipping carton box 20	146 mm x 146 mm x 235 mm	5.01 dm ³	386.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

Guarantee terms are available at
▶ www.osram.com/am-guarantee

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.