

64193CBI

COOL BLUE INTENSE | Halogen headlight lamps for cars



Areas of application

- Headlight
- Ideal for use in clear-glass headlights

Product benefits

- Stylish look
- Up to 20 % more light (compared to standard halogen lamps)
- Bluish white light for xenon look

Product features

- Color temperature: up to 4,200 K
- High luminous flux
- Headlight lamp for bluest legally approved halogen light
- Modern design with a silver cap (H4/H7)

Technical data

Electrical data


Power input	75 / 68 W ¹⁾
Nominal wattage	60 W
Nominal voltage	12 V
Test voltage	13.2 V

¹⁾ Maximum

Light technical data

Color temperature	4100 K
Luminous flux tolerance	±12 / ±15 %

Dimensions & weight

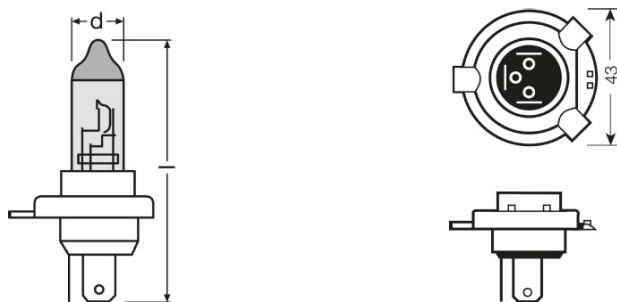

Product line drawing

Base

Length	82.0 mm
Diameter	17.0 mm
Product weight	25.60 g

Lifespan

Lifespan B3	50 / 200 h ¹⁾
Lifespan Tc	100 / 400 h ¹⁾

¹⁾ Filament 1 / Filament 2

Additional product data

Base (standard designation)	P43t
-----------------------------	------

Product datasheet

Certificates & standards

ECE category	H4
--------------	----

Country specific categorizations

Order reference	64193CBI
-----------------	----------

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.