
2721

Lamps with glass wedge bases for cars



Product benefits

- Wide product range
- Reliable quality

Product features

- Original spare parts

Product datasheet

Technical data


Electrical data

Power input	1.22 W
Nominal wattage	1.20 W
Nominal voltage	12 V
Power input tolerance	±15 %
Test voltage	13.5 V

Photometrical data

Luminous flux	7.5 lm
Luminous flux tolerance	±20 %

Dimensions & weight

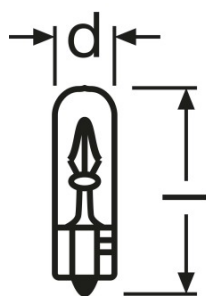

Length	22.6 mm
Diameter	5.0 mm

Lifespan

Lifespan B3	500 h
Lifespan Tc	2000 h

Additional product data

Base (standard designation)	W2x4.6d
-----------------------------	---------

Certificates & standards

ECE category	-
--------------	---

Country specific categorizations

Order reference	2721 1,2W12VW2X
-----------------	-----------------

Product datasheet

Country specific information

Product code	METEL code	SEG number	STK number	UK Org
4050300838540	OSRA2721	8328264	8328264	-
4050300925769	-	8328282	8328282	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300838540	2721	Unpacked 1	20 mm x 8 mm x 9 mm	0.00 dm ³	2.43 g
4050300524887	2721	Folding carton box 10	29 mm x 59 mm x 113 mm	0.19 dm ³	20.75 g
4008321094797	2721	Shipping carton box 50	148 mm x 55 mm x 115 mm	0.94 dm ³	104.80 g
4050300925769	2721	Blister 2	75 mm x 12 mm x 36 mm	0.03 dm ³	5.79 g
4008321140326	2721	Shipping carton box 20	137 mm x 105 mm x 80 mm	1.15 dm ³	100.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.