

## 8022

Lamps without halogen, low voltage



### Areas of application

- As film projector lamps




# Product datasheet

## Technical data

### Electrical data

Nominal voltage	12.0 V
Nominal wattage	50.00 W
Lamp wattage	50 W

### Dimensions & weight

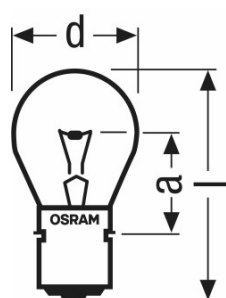

BA20d  
IEC 7004-12  
DIN 49730

IEC 7005-14  
DIN 49735

Diameter	35.0 mm
Light center length (LCL)	39.5 mm
Length	69.0 mm

### Lifespan

Lifespan	50 h
----------	------

### Additional product data

Base (standard designation)	BA20d
-----------------------------	-------

### Capabilities

Burning position	h105
------------------	------

### Country specific categorizations

Order reference	8022 50W 12V BA
-----------------	-----------------

## Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300206677	OSRF8022	-	4739348	-

## Product datasheet



### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300206677	8022	Folding carton box 1	36 mm x 36 mm x 69 mm	0.09 dm <sup>3</sup>	17.00 g
4050300206684	8022	Shipping carton box 100	191 mm x 163 mm x 366 mm	11.39 dm <sup>3</sup>	2800.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.