



Professionally approved products.

Product Datasheet

RS Ethernet Converter (RJ45-BNC)






Features

- 10M Ethernet 10Base-T/2converter
- RJ-45 connector for UTP interface
- UTP CAT 3 or 5 cable up to 100-meter

Specifications

- IEEE Standard: IEEE802.3 10Base-T/10Base-2
- Network Connector
 - 1x UTP RJ-45 Jacks,
 - 1x BNC Connector Network Cable
- LED
 - UTP: Cat.3 UTP cable
 - Coaxial: RG-58A/U thin cable
- Maximum wire Length
 - UTP: 100m
 - Coaxial: 185m per segment
- Data Transfer Rate: 10Mbps
- LED Indicator: BNC ACT, Power, TP Link/Activity, Collision
- Power Supply: External Power Adapter DC5V1A
- Environment
 - Operating temperature : 0°C to 50°C
 - Operating Humidity: 5% to 90% (Non-Condensing)
- Dimension: 26.2 x 70.3 x 94 mm
- Certification: FCC, CE

Package

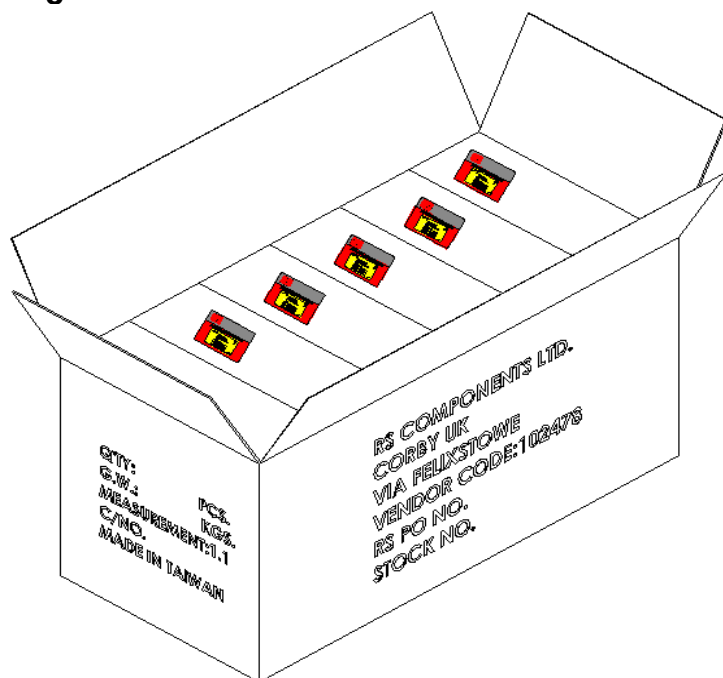

1 carton/8 pcs