

4AA ProPolymer® LED Alkaline Battery-Powered Flashlight



Case Material/Lens: Impact resistant polymer. Features a rubber face cap for impact and shock resistance. Unbreakable polycarbonate lens with scratch-resistant coating

Dimensions/Weight: Length: 6.5 in. (16.51 cm) Diameter: 1.63 in. (4.14 cm) Width: 1.34 in. (3.40 cm)
Weight: 6.3 ounces

Light Source: Seven 100,000 hour life white LEDs

Output/Run Time: 67 lumens; runs 155 hours

On/Off: Push button tail switch provides one handed momentary or constant operation

Battery: Four "AA" alkaline batteries (included)

- Features:**
- Waterproof
 - Ergonomically shaped for maximum hand comfort
 - Non-conductive
 - Corrosion proof
 - Wrist lanyard connection

- Approvals:**
- UL -US Class I, Div. 1, Groups C,D; Class I, Div 2, Groups A,B,C,D; Class II, Div. 2, Groups F,G; Class III, T3C
 - C-UL Class I, Div. 2, Groups A,B,C,D; Class II, Div. 2, Groups F,G; Class III, T3C
 - Permissible for use in Gassy Mines, Methane/air only. Appr. No. 10C-658-0

Warranty: Streamlight warrants this product to be free of defects for a lifetime of use except for batteries and bulbs, abuse and normal wear. We will repair, replace or refund the purchase price of this product should we determine it to be defective. This limited lifetime warranty also excludes rechargeable batteries, chargers, switches and electronics which have a 2 year warranty with proof of purchase. THIS IS THE ONLY WARRANTY, EXPRESSED OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. INCIDENTAL, CONSEQUENTIAL OR SPECIAL DAMAGES ARE EXPRESSLY DISCLAIMED EXCEPT WHERE SUCH LIMITATION IS PROHIBITED BY LAW. You may have other specific legal rights which vary by jurisdiction.

Item		UPC	Part #
4AA ProPolymer LED - White LEDs and alkaline batteries. Blister	Yellow	080926-68202-3	68202
4AA ProPolymer LED - White LEDs and alkaline batteries. Blister	Black	080926-68302-0	68302
4AA ProPolymer LED - White LEDs and alkaline batteries. Box	Yellow	080926-68201-6	68201
4AA ProPolymer LED - White LEDs and alkaline batteries. Box	Black	080926-68301-3	68301
4AA ProPolymer LED - White LEDs without alkaline batteries. Box	Yellow	080926-68200-9	68200
4AA ProPolymer LED - White LEDs without alkaline batteries. Box	Black	080926-68300-6	68300


See back for accessories

Adheres to side of hard hat



Poly Mount Kit universal mounting via slot attachment or self-adhesive mount

Includes straps for mounting the 4AA ProPolymax/3AA/4AA ProPolymer HAZ-LO, 2AA ProPolymer® Series or the PolyTac® LED Series

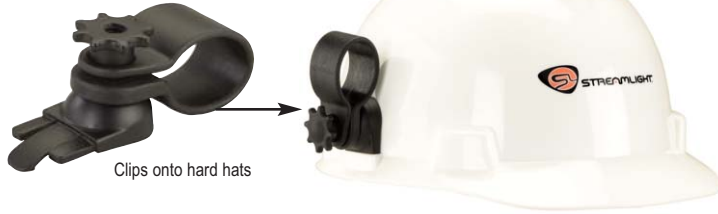

Clips onto hard hats



Helmet Strap.
Helmet and light not included.



Gallet Mount



Helmet Mount



Item	UPC	Part #	
4AA White LED Lamp Module	080926-68221-4	68221	
4AA Blue LED Lamp Module	080926-68222-1	68222	
Nylon Holster	080926-68905-3	68905	
Safety Wand	Yellow	080926-75904-6	75904
Safety Wand	Red	080926-75903-9	75903
Safety Wand	Blue	080926-75902-2	75902
Safety Wand	White	080926-75908-4	75908
Safety Wand	Glow-in-the-dark	080926-75913-8	75913
Rubber Helmet Strap	080926-99075-3	99075	
Poly Mount	080926-68089-0	68089	
3AA/4AA Helmet Mount	080926-68085-2	68085	
3AA/4AA Gallet Helmet Mount	080926-68086-9	68086	
3AA/4AA Gallet Helmet Mount (fits Gallet F1S, F1SF, F2)	080926-68130-9	68130	

