

Level Sensors Capacitive Type A94-20



- Level sensor for pools
- 3 mm sensing distance
- For wall mounting

Product Description

Hanging capacitive level sensor for (swimming) pools. For use with amplifiers H494 and S194.

Ordering Key

A94-20

Type _____

Type Selection


Ordering no. _____

A 94-20

Specifications

Rated operational voltage	7,5-9 VDC through 220 Ω	Rated operating distance	3 mm \pm 1 mm
Rated operational current		Environment	
Active	< 8,0 mA	Degree of protection	IP 67
Inactive	> 2,5 mA	Operating temperature	-25° to +70°C (-13° to +158°F)
Frequency of operating cycles (f)	10 Hz	Storage temperature	-40° to +85°C (-40° to +185°F)
Indication for output ON	No	Housing material	Thermoplastic polyester
		Cable	PVC, 5 m

Dimensions

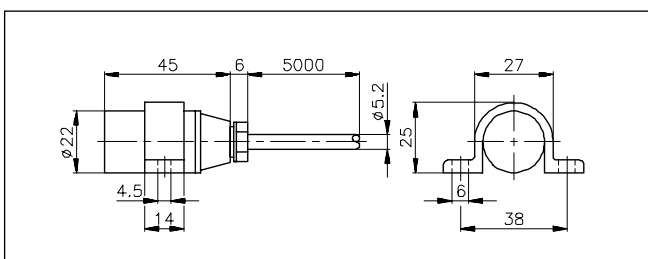

Wiring Diagram

