

MUSHROOM PUSHBUTTON, 22MM, ROUND, METAL, SHINY, YELLOW, 40MM, POSITIVE LATCHING, ROTATE TO UNLATCH



Figure similar

| | |
|-----------------------|----------------------------------|
| product brand name | SIRIUS ACT |
| Product designation | Commanding and signaling devices |
| Design of the product | Mushroom pushbutton |

| Actuator: | |
|---|-----------------------------------|
| Design of the operating mechanism | Mushroom pushbutton, tamper-proof |
| Manner of function of the actuating element | Latching |
| Product expansion optional Light source | No |
| Color | |
| • of the actuating element | Yellow |
| Material of the actuating element | plastic |
| Shape of the actuating element | round |
| Outer diameter of the actuating element | 40 mm |
| Type of unlocking device | rotate-to-unlatch mechanism |
| Number of switching positions | 2 |

| Front ring: | |
|------------------------------|---------|
| Product component front ring | No |
| Design of the front ring | without |

General technical data:

| | |
|---|-----------------------------------|
| Product function | |
| • EMERGENCY OFF function | Yes |
| • EMERGENCY STOP function | Yes |
| Protection class IP | IP66, IP67, IP69(IP69K) |
| Degree of protection NEMA | NEMA 1, 2, 3, 3R, 4, 4X, 12 |
| Shock resistance | |
| • acc. to IEC 60068-2-27 | Sinusoidal half-wave 50 g / 11 ms |
| Vibration resistance | |
| • acc. to IEC 60068-2-6 | 10 ... 500 Hz: 5g |
| Operating frequency maximum | 600 1/h |
| Mechanical service life (switching cycles) | |
| • typical | 300 000 |
| Equipment marking | |
| • acc. to DIN EN 61346-2 | S |
| • acc. to DIN EN 81346-2 | S |

Ambient conditions:

| | |
|--|--------------------|
| Ambient temperature | |
| • during operation | -25 ... +70 °C |
| • during storage | -40 ... +80 °C |
| Environmental category during operation acc. to IEC 60721 | 3K6, 3C3, 3S2, 3M6 |

Installation/ mounting/ dimensions:

| | |
|--|---------|
| Height | 40 mm |
| Width | 40 mm |
| Shape of the installation opening | round |
| Mounting diameter | 22 mm |
| Mounting height | 45.3 mm |
| Installation width | 40 mm |
| Installation depth | 26.3 mm |

Certificates/ approvals:

| | |
|---------------------------------------|-------------------------------|
| For use in hazardous locations | other |
| Herstellererklärung | Bestätigungen |

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mfb=3SU10501HB300AA0>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SU10501HB300AA0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)


<https://support.industry.siemens.com/cs/ww/en/ps/3SU10501HB300AA0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SU10501HB300AA0&lang=en

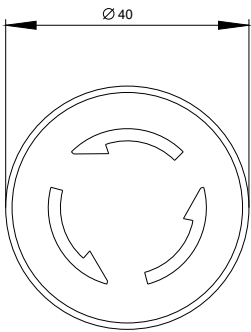

last modified:

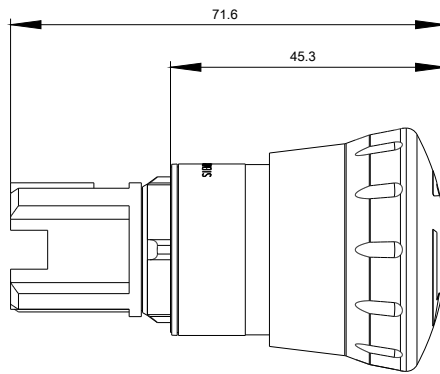

14.09.2015