

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1120955041](#)  
**Status:** **Active**  
**Overview:** IP67-Rated HarshIO Modules  
**Description:** Brad HarshIO Digital Module for EtherNet/IP QuickConnect, Classic 60mm, IP67, 8 ports M12, 8 Inputs / 8 Outputs, PNP, 4 Pole Power  
**Replacement Part Number:** [http://www.molex.com/molex/products/listview.jsp?channel=Products&sType=p&query=1120955138112095-5138 w/differences](http://www.molex.com/molex/products/listview.jsp?channel=Products&sType=p&query=1120955138112095-5138%20w/differences)

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)

**Agency Certification**

UL E200650

**General**

Product Family Industrial I/O Modules  
 Series [112095](#)  
 Application Filling and Packaging Machines, Machine Tool Industry, Material Handling Systems  
 Approvals ODVA, UL, cUL, CE  
 Current - Maximum Output 2.0A per Channel  
 EPLAN Yes  
 Format Classic (60mm)  
 I/O Ports 8x M12  
 IP Rating IP67  
 Mechanical Shock 10G, 11ms, 3 AXIS  
 Overview [IP67-Rated HarshIO Modules](#)  
 Product Literature Order No 987650-7165  
 Product Name HarshIO EtherNet/IP  
 Protocol EtherNet/IP  
 Replacement Part Number [112095-5138](#) w/differences  
 Software Downloads TCDEI-8xxP-DxU-G  
 UPC 884982493179

**Physical**

Bus Input 4-pole Micro-Change (M12), D-Coded, Female  
 Bus Output 4-pole Micro-Change (M12), D-Coded, Female  
 Housing Width 60.00mm  
 I/O Connector 5-pole Ultra-Lock (M12), A-Coded, Female  
 I/O Signal Mix 8 input / 8 output  
 Net Weight 0.538/kg  
 Power Input 4-pole Mini-Change, Male  
 Power Output 4-pole Mini-Change, Female  
 Temperature Range - Operating -25°C to +70°C  
 Vibration IEC 60068-2-6

**Electrical**


EMC IEC 61000-6-2  
 Input Delay 5 ms  
 Input Device Supply 140 mA per port at 25°C  
 Input Type PNP or Dry Contact

**Material Info**

Engineering Number TCDEI-888P-DYU-G

**Reference - Drawing Numbers**

Sales Drawing 1120950007-000, SD-112095-0002

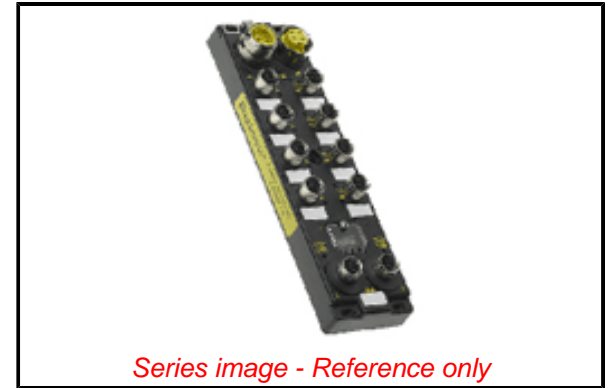

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[112095](#) Series

This document was generated on 08/27/2018

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**