



SPECIFICATION SHEET

385-FRCJ



16 CAL/CM² DUAL CERTIFIED CARPENTER JEANS

- Arc Rating: ATPV 16.4 cal/cm²
- PPE 2 (HRC 2)
- 13 oz FR Denim
- Contrast topstitching with aramid high tenacity FR thread
- All metal thermally protected from the skin
- Bar-tacked at all stress points
- One-way heavy duty #5 brass zipper on aramid tape
- 2 curved waist pockets, 1 coin pocket at right side, 2 rear hip patch pockets, hammer loop on left leg and tool pocket on right leg
- One set copper jeans button at front waistband

STANDARDS MET

- NFPA 70E / ASTM F1506
- NFPA 2112-2012
- NFPA 1975-2009
- CAN/CGSB 155.20-2000, CAN/CGSB 155.22-97, et OSHA 29 CFR 1910.269
- EN ISO 11611:2008, EN ISO 11612:2008, EN ISO 14116:2008

APPLICATIONS

- Electrical & utilities
- Petrochemical, oil & gas
- Mining
- Welding

CARE INSTRUCTIONS

Machine wash warm, tumble dry low. Wash with synthetic detergents. Wash separate from everyday clothing in small loads FR clothing is dry cleanable. DO NOT use bleach, fabric softener or dryer sheets

TECHNICAL DATA

MATERIAL	100% Cotton
CONSTRUCTION	Main: Denim FR twill weave Acc: Aramid high tenacity FR thread
COLOR	■ Blue Denim
SIZES	30 x 30 - 50 x 36
PACKAGING	1/Polybag
CASE	20.5" x 15.4" x 9.1" / 52cm x 39cm x 23cm
CASE WEIGHT	22 lbs / 10 kg
COO	China


BARCODES (Continues on next page)

ITEM	EACH	BOX	CASE
■ 385-FRCJ-3030	616314163050	01616314163059	02616314163058
■ 385-FRCJ-3032	616314163067	01616314163066	02616314163065
■ 385-FRCJ-3034	616314163074	01616314163073	02616314163072
■ 385-FRCJ-3036	616314163081	01616314163080	02616314163089
■ 385-FRCJ-3230	616314163098	01616314163097	02616314163096
■ 385-FRCJ-3232	616314163104	01616314163103	02616314163102
■ 385-FRCJ-3234	616314163111	01616314163110	02616314163119



DIMENSIONS (in)

	30	32	34	36	38	40	42	44	46	48	50	
A	--	31.5	33.5	35.5	37.5	39.5	41.5	43.5	45.5	47.5	49.5	51.5
B	30	31.75	31.75	31.75	31.75	31.75	31.75	31.75	31.75	31.75	31.75	31.75
	32	33.75	33.75	33.75	33.75	33.75	33.75	33.75	33.75	33.75	33.75	33.75
	34	35.75	35.75	35.75	35.75	35.75	35.75	35.75	35.75	35.75	35.75	35.75
	36	37.75	37.75	37.75	37.75	37.75	37.75	37.75	37.75	37.75	37.75	37.75

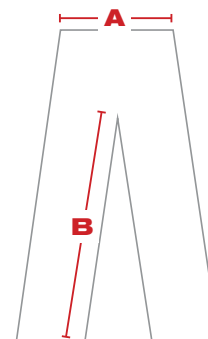



SPECIFICATION SHEET

385-FRCJ

BARCODES (Continued)

385-FRCJ-3236	616314163128	01616314163127	02616314163126
385-FRCJ-3430	616314163135	01616314163134	02616314163133
385-FRCJ-3432	616314163142	01616314163141	02616314163140
ITEM	EACH	BOX	CASE
385-FRCJ-3434	616314163159	01616314163158	02616314163157
385-FRCJ-3436	616314163166	01616314163165	02616314163164
385-FRCJ-3630	616314163173	01616314163172	02616314163171
385-FRCJ-3632	616314163180	01616314163189	02616314163188
385-FRCJ-3634	616314163197	01616314163196	02616314163195
385-FRCJ-3636	616314163203	01616314163202	02616314163201
385-FRCJ-3830	616314163210	01616314163219	02616314163218
385-FRCJ-3832	616314163227	01616314163226	02616314163225
385-FRCJ-3834	616314163234	01616314163233	02616314163232
385-FRCJ-3836	616314163241	01616314163240	02616314163249
385-FRCJ-4236	616314163258	01616314163257	02616314163256
385-FRCJ-4430	616314163265	01616314163264	02616314163263
385-FRCJ-4432	616314163272	01616314163271	02616314163270
385-FRCJ-4434	616314163289	01616314163288	02616314163287
385-FRCJ-4436	616314163296	01616314163295	02616314163294
385-FRCJ-4630	616314163302	01616314163301	02616314163300
385-FRCJ-4632	616314163319	01616314163318	02616314163317
385-FRCJ-4634	616314163326	01616314163325	02616314163324
385-FRCJ-4636	616314163333	01616314163332	02616314163331
385-FRCJ-4830	616314163340	01616314163349	02616314163348
385-FRCJ-4832	616314163357	01616314163356	02616314163355
385-FRCJ-4834	616314163364	01616314163363	02616314163362
385-FRCJ-4836	616314163371	01616314163370	02616314163379
385-FRCJ-5030	616314163388	01616314163387	02616314163386
385-FRCJ-5032	616314163395	01616314163394	02616314163393
385-FRCJ-5034	616314163401	01616314163400	02616314163409
385-FRCJ-5036	616314163418	01616314163417	02616314163416