


# Data sheet

## Glassfibre Exposed Welded Tip Thermocouples – BS Colours

Types K or J, 2 metres long with tail wires – BS1843 colour code

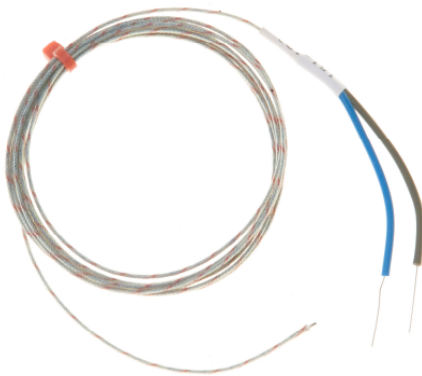

Type 'K'



Type 'J'

- Thermocouple types K or J
- Fast response, welded exposed junction
- 2 metre long glassfibre insulated flat pair cable
- Good temperature resistance (not suitable in fluids)
- 1/0.3mm conductors
- Colour coded tail wires
- Temperature range  $-60^{\circ}\text{C}$  to  $+350^{\circ}\text{C}$  (short periods up to  $400^{\circ}\text{C}$ )
- Colour coded to former British Standard – BS1843-1952
- Tolerance in accordance with IEC 584 class 2
- Ideal for test & development applications

T/C Type	Conductors	Length	Termination	+Positive tail wire	-Negative tail wire	RS order code
'K'	1/0.3mm	2 metres	Colour coded tails	Brown	Blue	151-192
'J'	1/0.3mm	2 metres	Colour coded tails	Yellow	Blue	150-004