





# Timing Pulleys XL


(0.200" / 5.08mm pitch)  
for 9.53mm (3/8") wide belt  
Centre drilled or Pilot Bore  
in Aluminium with Zinc plated Steel Flanges

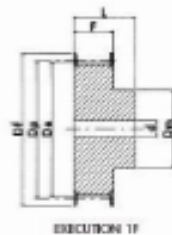

EXECUTION 1F

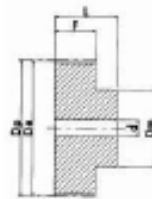

EXECUTION 2

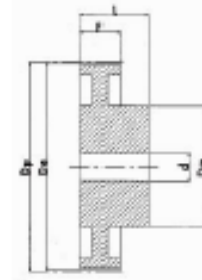

execution 3

## Dimensions

Please note : All dimensions subject to change.

Pulleys may be Bored or Unbored.

If a dimension is critical to your application please contact our sales department for confirmation.  
for [special pulleys](#) or [reworked](#) pulleys please contact our manufacturing department

| Code      | Type | No. Teeth | Dp     | De     | Df | Dm   | F    | L  | Bore | No. Flanges |
|-----------|------|-----------|--------|--------|----|------|------|----|------|-------------|
| P10XL037F | 1F   | 10        | 16.17  | 15.66  | 23 | 9.5  | 14.3 | 20 | -    | 2           |
| P11XL037F | 1F   | 11        | 17.79  | 17.28  | 23 | 9.5  | 14.3 | 20 | -    | 2           |
| P12XL037F | 1F   | 12        | 19.40  | 18.90  | 25 | 10   | 14.3 | 20 | -    | 2           |
| P13XL037F | 1F   | 13        | 21.02  | 20.51  | 25 | 10   | 14.3 | 20 | -    | 2           |
| P14XL037F | 1F   | 14        | 22.64  | 22.13  | 28 | 15   | 14.3 | 20 | -    | 2           |
| P15XL037F | 1F   | 15        | 24.26  | 23.75  | 28 | 15   | 14.3 | 20 | -    | 2           |
| P16XL037F | 1F   | 16        | 25.87  | 25.36  | 32 | 16   | 14.3 | 20 | -    | 2           |
| P17XL037F | 1F   | 17        | 27.49  | 26.98  | 32 | 20   | 14.3 | 20 | -    | 2           |
| P18XL037F | 1F   | 18        | 29.11  | 28.60  | 35 | 20   | 14.3 | 20 | -    | 2           |
| P19XL037F | 1F   | 19        | 30.72  | 30.22  | 35 | 20   | 14.3 | 22 | -    | 2           |
| P20XL037F | 1F   | 20        | 32.34  | 31.83  | 38 | 23.5 | 14.3 | 22 | -    | 2           |
| P21XL037F | 1F   | 21        | 33.96  | 33.45  | 38 | 23.5 | 14.3 | 22 | -    | 2           |
| P22XL037F | 1F   | 22        | 35.57  | 35.07  | 41 | 25   | 14.3 | 22 | 6    | 2           |
| P24XL037F | 1F   | 24        | 38.81  | 38.30  | 44 | 30   | 14.3 | 22 | 6    | 2           |
| P26XL037F | 1F   | 26        | 42.04  | 41.53  | 48 | 30   | 14.3 | 22 | 8    | 2           |
| P27XL037F | 1F   | 27        | 43.66  | 43.15  | 48 | 30   | 14.3 | 22 | 8    | 2           |
| P28XL037F | 1F   | 28        | 45.28  | 44.77  | 51 | 34   | 14.3 | 22 | 8    | 2           |
| P30XL037F | 1F   | 30        | 48.51  | 48.00  | 54 | 38   | 14.3 | 22 | 8    | 2           |
| P32XL037F | 1F   | 32        | 51.74  | 51.24  | 57 | 38   | 14.3 | 25 | 8    | 2           |
| P34XL037F | 1F   | 34        | 54.98  | 54.47  | 61 | 38   | 14.3 | 25 | 8    | 2           |
| P35XL037F | 1F   | 35        | 56.60  | 56.09  | 61 | 38   | 14.3 | 25 | 8    | 2           |
| P36XL037  | 2    | 36        | 58.21  | 57.70  | -  | 45   | 14.3 | 25 | 8    | 0           |
| P38XL037  | 2    | 38        | 61.45  | 60.94  | -  | 45   | 14.3 | 25 | 8    | 0           |
| P40XL037  | 2    | 40        | 64.68  | 64.17  | -  | 45   | 14.3 | 25 | 8    | 0           |
| P42XL037  | 2    | 42        | 67.91  | 67.41  | -  | 45   | 14.3 | 25 | 8    | 0           |
| P44XL037  | 2    | 44        | 71.15  | 70.64  | -  | 45   | 14.3 | 25 | 8    | 0           |
| P48XL037  | 3    | 48        | 77.62  | 77.11  | -  | 45   | 14.3 | 25 | 10   | 0           |
| P60XL037  | 3    | 60        | 97.02  | 96.51  | -  | 45   | 14.3 | 25 | 10   | 0           |
| P72XL037  | 3    | 72        | 116.42 | 115.92 | -  | 45   | 14.3 | 25 | 10   | 0           |