


RS ITEM NO 205-511

ITEM NO T1SB12A



LED/Multiled	<i>LED</i>	Optimum voltage (V)	<i>12Vac/dc</i>	Intensity	<i>550mcd Typ</i>
Mounting Size	<i>Bi-Pin</i>	Rectifier	-	Reverse Voltage	<i>5Vdc</i>
Mounting Finish	-	AC current	<i>6mA</i>		
Protection	-	DC current	<i>12mA</i>		
Mount Holder	-	Voltage Tolerance(%)	<i>10%</i>		
Chip Qty	-	Optimum temperature (°C)	<i>-25°C...+60°C</i>		
Indicator colour	<i>Blue</i>	Storage temperature (°C)	<i>-25°C...+60°C</i>		
Wavelength (nm)	<i>470nm</i>	Contact Tab	<i>Bi-Pin</i>		

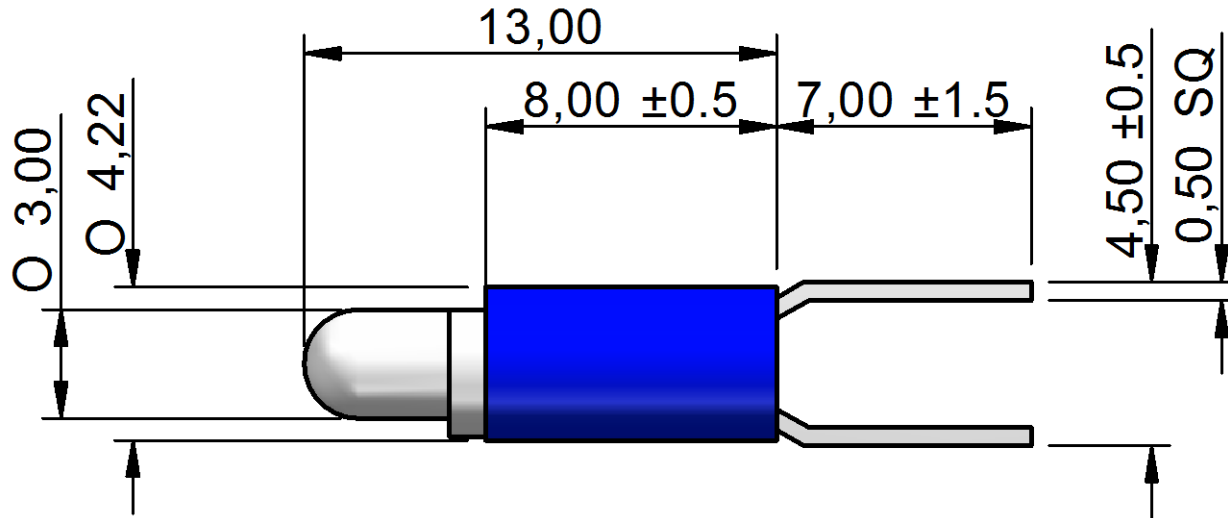

*Dimension in mm (typical), not to scale.
We reserve the right to make changes without further notice to this product to improve reliability, function or design.*