

MECHANICAL

INSULATOR MATERIAL
PBT & Glass-fibre reinforced
UL 94V-0

CONTACT
Brass

SHELL
Steel

FINISH
Contact: Gold Flash
Shell: Nickel or Tin

DURABILITY
100 cycles

ELECTRICAL




CURRENT RATING
5 Amp

DIELECTRIC WITHSTANDING VOLTAGE
AC 1000V Min. (for 1 minute)

INSULATION RESISTANCE
1000M Ω Min. (at 500V DC)

CONTACT RESISTANCE
20m Ω Max.

WORKING TEMPERATURE
-55°C to +105°C

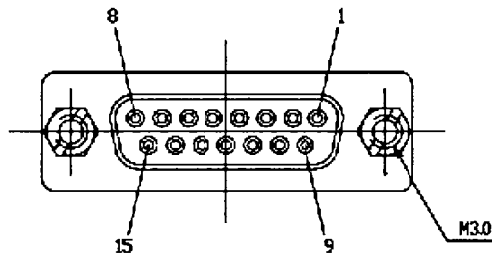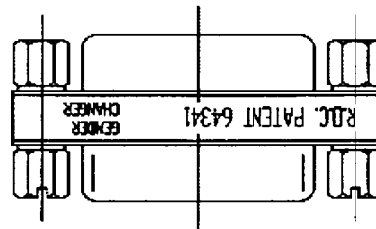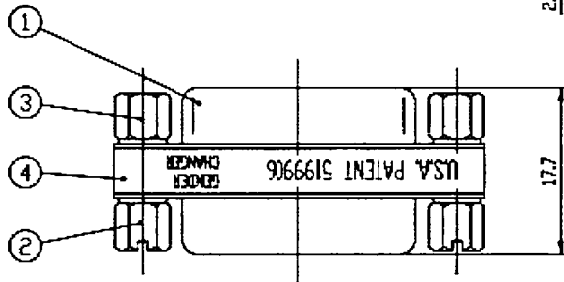

UNLESS OTHERWISE SPECIFIED TOLERANCE : X ±0.2 ANGLES : ±2' XX ±0.1 XXX ±0.05 DO NOT SCALE DRAWING		TITLE 15Way Mini Gender Changer	
DRAWN BY <i>Arhua</i>	CHECKED BY <i>[Signature]</i>	SCALE 1 : 1	PART NO. 218-223
APPROVED BY <i>[Signature]</i>	DWG NO. DEWX2001081901X0	ITEM NO. MGCD15F/D15F-01E	THIRD ANGLE PROJECTION PAGE 1 OF 1
DATE 06/19/2001			

4	Label , Yellow Color
3	#4-40 Hex Nuts
2	#4-40 Hex Screw
1	D-SUB 15 Female
No.	DESCRIPTION