


Data sheet

ADJUSTABLE BAYONET

RS Stock No.259-328

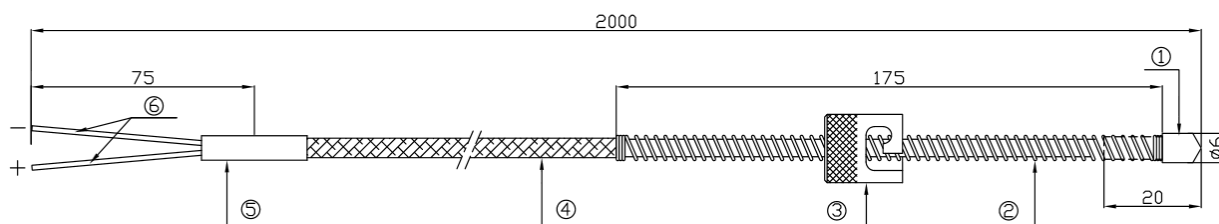

TYPE K ADJUSTABLE BAYONET

RANGE :

- -50 / 400°C

USE :

- Plastic Industry

KEY POINT :

- Fitting with adjustable bayonet

SPECIFICATIONS :

- Glass fiber insulation
- Stainless Steel braid

DIMENSIONS :

- Bolt = $\varnothing 11.3 \times 14.5\text{mm}$
- Length = 2000mm
- Section = 0.22mm^2

METROLOGICAL DATA :

- As per IEC 584
- Standard tolerance TC "K" class1:
 $-40^\circ\text{C} < t^\circ < 375^\circ\text{C} = \pm 1.5^\circ\text{C}$
 $375^\circ\text{C} < t^\circ < 1000^\circ\text{C} = \pm 0.004. [t]$
- Time constant at 63% in water: 0.7 sec
- Output signal FEM(mV) as per curve of "K" type as per norme IEC 60584