


Professionally approved products.

Datasheet

PVC Soundproofing Sheet, 1000mm x 600mm x 3mm

RS Stock number [293-108](#)

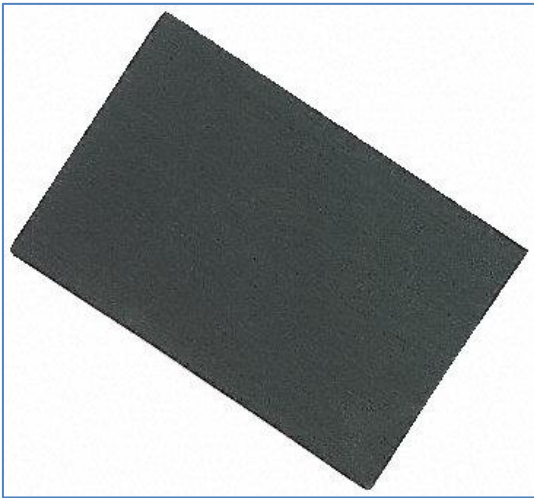

Description:

Thermo Plastic Rubber – Styrene based with butadiene loaded with filler white minerals.
Flexible Temperature Resistance: Flexible at -10°C

- Shrinkage tested at 80°C for 1 hour, across the grain 0%, with the grain 4%
- Non toxic and no irritating odours are given off

Specifications:

Specific Gravity:	1.95 / 2.05
Shore Hardness 0 A:	60
Tensile Strength MPa :	2.3
Elongation at Break %:	750
Weight per square meter @1.4 mm	3.4 kilo average