

Professionally approved products.


Datasheet

RS 15V dc Surface Mount Electromagnetic Buzzer, 85dB Continuous

RS Stock 457-049



Dimensions: (mm)

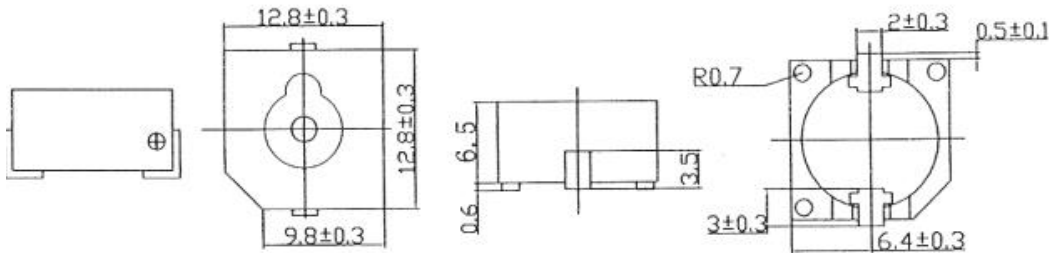

Features:

- Reflow solderable and washable
- Housing material: PPS
- Pin material: Brass

RoHS ✓

All data at 25°C unless otherwise specified.

SPECIFICATIONS	ABI-018-RC – Surface Mount Indicator
Rated Voltage	12VDC
Operating Voltage	8 ~ 15VDC
Rated Current at rated voltage	30mA
Sound Output at 10cm, at rated voltage	85dB
Resonant Frequency	2400±400Hz
Operating Temperature	-20 ~ +70°C
Storage Temperature	-30 ~ +80°C
Weight	2g