


Professionally approved products.

Datasheet

20 Way Universal Straight Plug, 44.70mm L


RS Stock number [471-058](#)

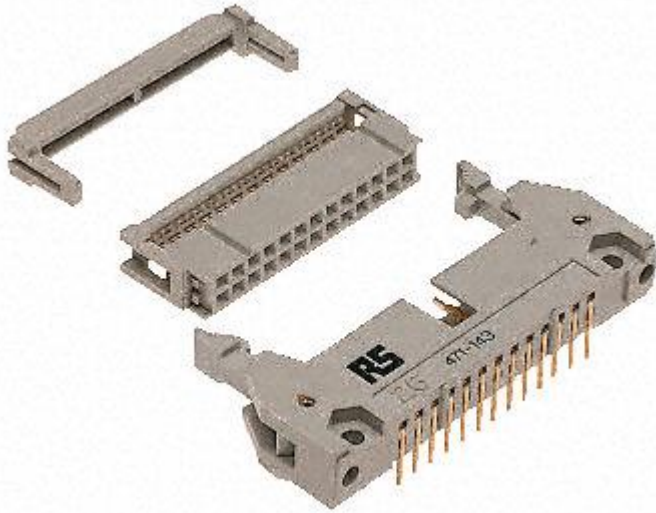

Specifications:

Current Rating:	1 Amp max.
Insulator Resistance:	5000MΩmin. at dc 500V
Contact Resistance:	6M ohm typical
Operating Temperature:	-55°C ~ +105°C
Housing:	30% glass filled PBT, Colour – Grey
Contacts:	Brass
Plating:	All gold flash over nickel

Professionally approved products. Datasheet

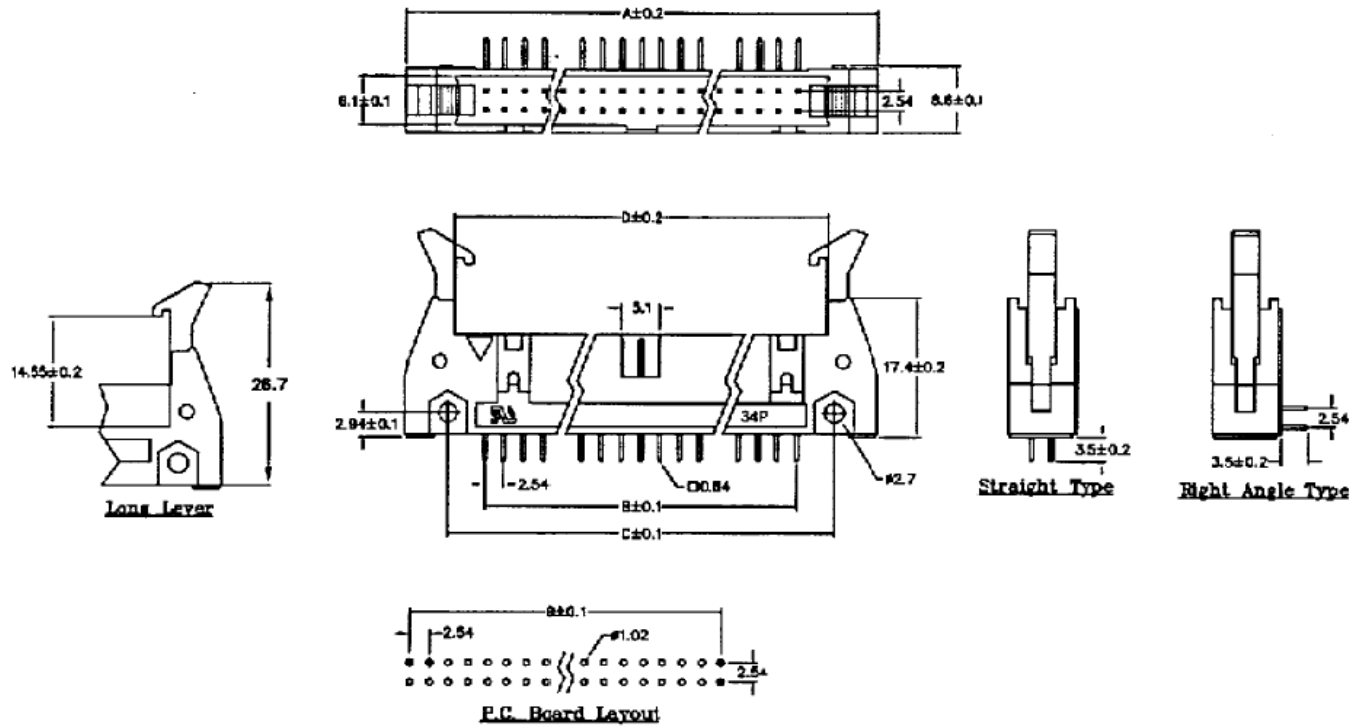

Position	Dimension			
	A	B	C	D
10	31.88	10.16	21.84	17.96
14	37.02	15.24	26.92	23.04
16	39.52	17.78	29.46	25.58
20	44.74	22.85	34.54	30.66
26	52.20	30.48	42.16	38.28
34	62.40	40.64	52.32	48.44
40	70.04	48.26	59.94	56.60
50	82.72	60.96	72.64	68.76
60	95.40	73.66	85.34	81.46
64	100.50	78.74	90.42	86.54