

Professionally approved products.



Datasheet

RS 2.77mm Pitch 37 Way IDC D-sub Connector, Socket, Zinc Plated Steel Shell


RS Stock number 492-658




Dimensions: (mm)

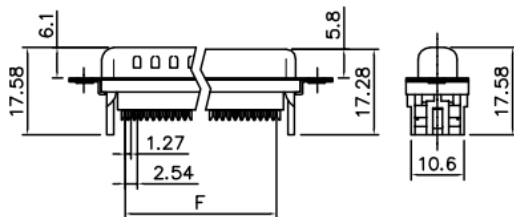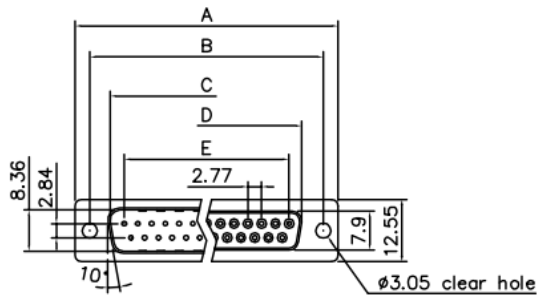


Without Insulator Support

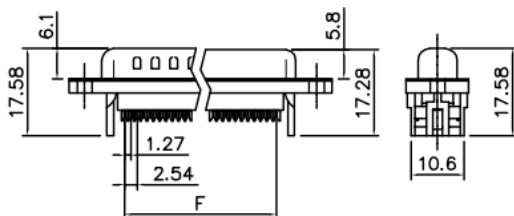

With Insulator Support

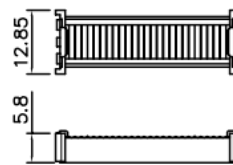

Cover

 

Strain Relief

Professionally approved products.

Datasheet

Product Specification

Material

Insulator : Glass-Filled Thermoplastic PBT, UL94V-0

Contact : Brass

Shell : Steel, 100u" Tin Over 50u" min Copper

Clinch Nut : Brass, Nickel Plated

Screwlock : Brass, Nickel Plated

Electrical

Contact Resistance : 20 milliohms
Max at 1 AMP DC.

Insulation Resistance : 1000
magohms at 500 VDC

Dielectric Withstanding Voltage :
1000 VAC/rms 60Hz for 1 minute



Current Rating : 3 AMP

Volatge Rating : 250 VAC/rms 60Hz


RoHS COMPLIANT

Professionally approved products.



Datasheet

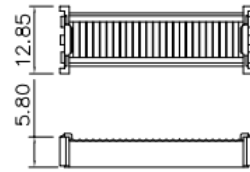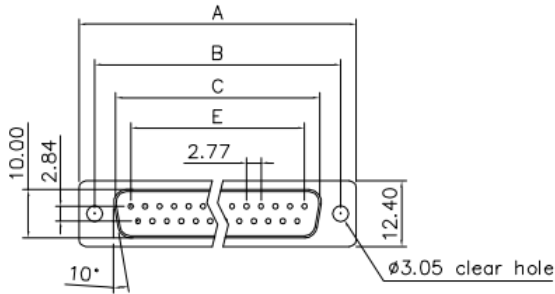

Cover

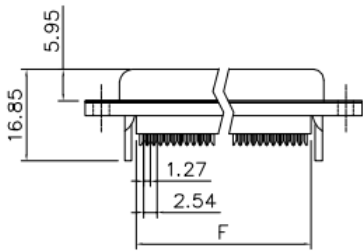

With Insulator Support

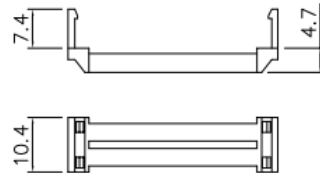 

Strain Relief

Product Specification

Material

Insulator : Glass-Filled Thermoplastic PBT, UL94V-0

Contact : Copper alloy

Electrical

Contact Resistance : 20 milliohms
Max at 1 AMP DC.

Insulation Resistance : 1000
magohms at 500 VDC

Dielectric Withstanding Voltage :
1000 VAC/rms 60Hz for 1 minute



Current Rating : 3 AMP

Volatge Rating : 250 VAC/rms 60Hz


RoHS COMPLIANT

Professionally approved products.


Datasheet

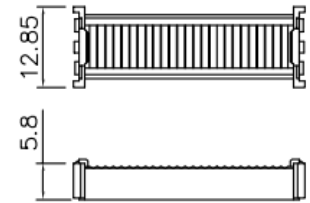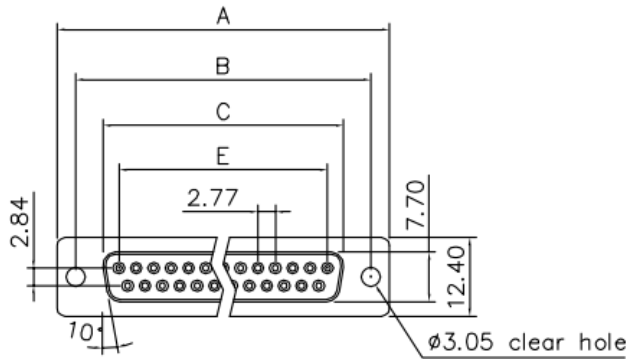

Cover

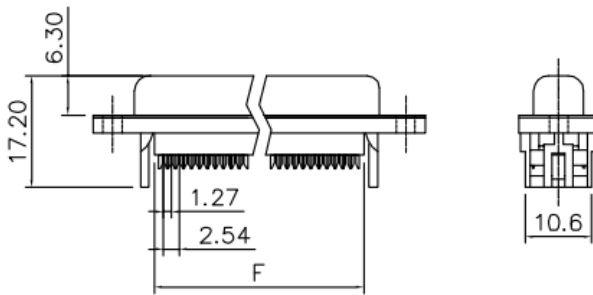

With Insulator Support

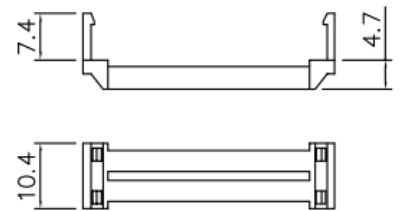

Strain Relief

Product Specification

Material

Insulator : Glass-Filled Thermoplastic PBT, UL94V-0

Contact : Copper alloy

Electrical

Contact Resistance : 20 milliohms
Max at 1 AMP DC.

Insulation Resistance : 1000
magohms at 500 VDC

Dielectric Withstanding Voltage :
1000 VAC/rms 60Hz for 1 minute

Current Rating : 3 AMP

Volatge Rating : 250 VAC/rms 60Hz

RoHS COMPLIANT

Professionally approved products.

Datasheet

f: Flange Mounting Option:

