


Datasheet

Stock No: 504-026

# RS Pro 100VA 2 Output Chassis Mounting Transformer, 6V ac

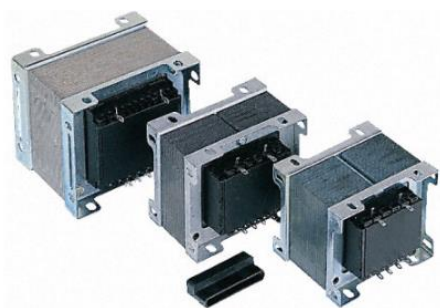

## Product Details

### Chassis Mount Frame 75VA to 200VA

The two independent secondary windings may be connected in series or parallel to give a wide range of output voltage and current options.

Optional terminal shrouds for 75VA and 100VA(503-928)

### Laminated Frame 230Vac Primary 75VA to 200VA (Multi Tapped)

Chassis mounting frame construction low voltage mains transformers with a single 230Vac 50/60Hz primary winding.

Double section bobbin construction

Fully shrouded bobbins

Full varnish impregnation

Multi-hole frame fixing

Solder tag terminations

100% electrical and flash tested

Tested in accordance with BS3535 and EN 60 742

## Specifications

Primary Voltage Rating	230V
Secondary Voltage Rating	6V ac
Power Rating	100VA
Number of Outputs	2
Mounting Type	Chassis
CAD Drawing	3D CAD Model
Length	89mm
Width	68mm
Depth	75mm
Dimensions	89 x 68 x 75mm
Fixing Hole Diameter	4.7 x 7.9mm
Weight	1.6kg
Minimum Operating Frequency	50Hz
Maximum Operating Frequency	60Hz