

RS P/N		A	B	C	D	E	COLOUR
498-889-0001	CS216-15T2D	15.0	15.0	12.0	13.0	3.5	SILVER
498-873-0001	CS216-20T2D	20.0	15.0	15.0	13.0	4.0	SILVER
498-867-0001	CS216-25T2D	25.0	15.0	18.0	13.0	4.5	SILVER
498-851-0001	CS216-30T2D	30.0	15.0	25.0	13.0	5.0	SILVER



CS216-15T2D




CS216-20T2D



CS216-25T2D



CS216-30T2D

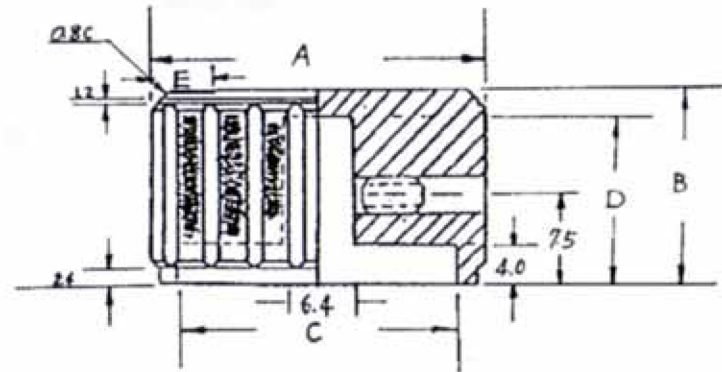

Material: ALUMINUM
Tolerance: +/-0.20
Unit : mm

P/N:		Date: 6-Dec-13
	CS216-T SERIES	