


Professionally approved products.

## Datasheet

# Insulated Crimp Spade Connector

RS Stock number [534-610](#)

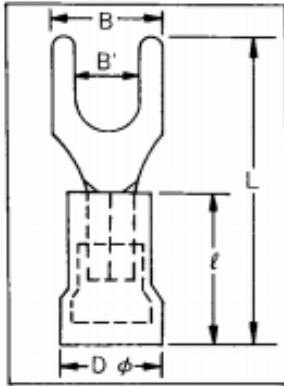

Insulated	Wire range		Colour	Dimensions(mm)				Stud size	
Stock no.	AWG	mm <sup>2</sup>		B	D φ	L	ε	AWG	mm
2082515	22-16	0.5-1.5	Red	5.7	4.3	20.5	9.9	4	3.2
534272	22-16	0.5-1.5	Red	6.4	4.3	20.0	9.9	6	3.7
534266	22-16	0.5-1.5	Red	6.4	4.3	20.5	9.9	8	4.3
534250	22-16	0.5-1.5	Red	8.5	4.3	25.0	9.9	10	5.3

Stock no.	AWG	mm <sup>2</sup>	Colour	B	D φ	L	ε	AWG	mm
534632	16-14	1.5-2.5	Blue	6.4	4.8	20.5	9.9	6	3.7
534626	16-14	1.5-2.5	Blue	6.4	4.8	20.5	9.9	8	4.3
534610	16-14	1.5-2.5	Blue	8.5	4.8	20.5	9.9	10	5.3

Stock no.	AWG	mm <sup>2</sup>	Colour	B	D φ	L	ε	AWG	mm
534503	12-10	2.5-6.0	Yellow	6.4	6.5	25.5	13.5	6	3.7