




549-599

- GB** **Blind Grommet Kit**
(Containing 263 blind grommets in 18 sizes)
- D** **BLINDAUGEN-SATZ**
(Enthält 263 Blindaugen in 18 Größen)
- F** **Kit d'oeillets borgnes**
(Contient 263 oeillets borgnes de 18 tailles)
- I** **Corredo Rosette Cieche**
(Contiene 263 rosette cieche in 18 misure)



- GB** Grommet material nylon 66
- D** Augenmaterial Nylon 66
- F** Oeillet en nylon 66
- I** Materiale delle rosette Nylon 66

Temperature range -20°C to + 105°C
 Temperaturbereich -20°C bis +105°C.
 Températures d'utilisation de -20°C à + 105°C
 Intervallo di temperatura -20°C a +105°C

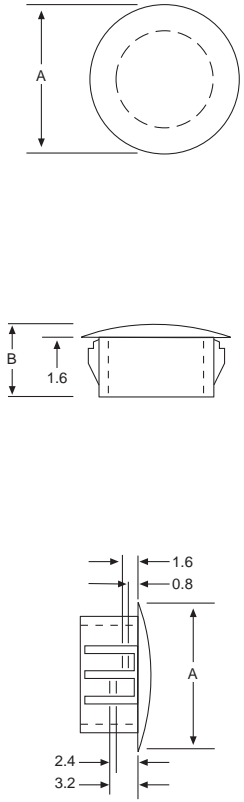

Mounting hole dia. Montageloch-Durchmesser Diamètre du trou de montage Diametro del foro di montaggio	4.8	6.4	8.0	9.5	11.0	12.7
Max. chassis thickness Maximum-Chassisdicke Epaisseur maximum du châssis Spessore massimo del telaio	1.6	1.6	1.6	3.2	3.2	3.2
Head dia. (A) Kopfdurchmesser (A) Diamètre de la tête. (A) Diametro della testa (A)	6.4	7.9	9.5	11.9	13.5	14.7
Overall height (B) Gesamthöhe (B) Hauteur totale (B) Altezza totale (B)	5.9	7.9	7.7	10.3	10.3	10.3
Mounting hole dia. Montageloch-Durchmesser Diamètre du trou de montage Diametro del foro di montaggio	14.3	15.9	17.5	19.0	20.6	22.2
Max. chassis thickness Maximum-Chassisdicke Epaisseur maximum du châssis Spessore massimo del telaio	3.2	3.2	3.2	3.2	3.2	3.2
Head dia. (A) Kopfdurchmesser (A) Diamètre de la tête. (A) Diametro della testa (A)	16.7	18.2	19.8	23.4	22.6	25.8
Overall height (B) Gesamthöhe (B) Hauteur totale (B) Altezza totale (B)	10.3	10.3	10.3	10.3	10.3	11.5
Mounting hole dia. Montageloch-Durchmesser Diamètre du trou de montage Diametro del foro di montaggio	25.4	27.8 to 28.6	32.0	35.0	38.0	45.0
Max. chassis thickness Maximum-Chassisdicke Epaisseur maximum du châssis Spessore massimo del telaio	3.2	3.2	3.2	3.2	3.2	3.2
Head dia. (A) Kopfdurchmesser (A) Diamètre de la tête. (A) Diametro della testa (A)	30.6	30.9	34.9	38.1	42.4	48.4
Overall height (B) Gesamthöhe (B) Hauteur totale (B) Altezza totale (B)	11.5	11.5	11.5	11.5	11.5	11.5

All dimensions in millimetres / Alle Maße in mm / Toutes les dimensions sont en millimètres / Tutte le dimensioni sono in millimetri