




Datasheet

Stock No: 215-5764

ENGLISH

RS Pro 100 μ F 50 V dc Aluminium Electrolytic Capacitor 1000h 10 (Dia.) x 16mm

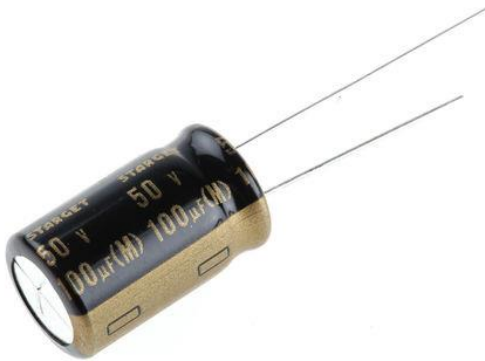

Product Details:

ARD (ROD) Series Starget

- Audio grade **polarised** electrolytic capacitors specifically designed for use where high performance and minimum distortion are required
- Oxygen-free copper lead-out wires

Capacitance Tolerance (%)	20
Operating Temperature (°C)	-40 → +85
Life Expectancy	1000 hrs at 85°C
Leakage current	0.01 CV or 3 μ A whichever is greater

Note

These Capacitors are Polarised



ENGLISH

Specifications:

Capacitance	100 μ F
Technology	Electrolytic
Voltage	50 V dc
Dimensions	10 (Dia.) x 16mm
Height	16mm
Diameter	10mm
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	+85°C
Lead Pitch	5mm
Construction	Radial
Series	ARD (ROD)
Tolerance	\pm 20%
Tolerance Minus	-20%
Ripple Current	250mA
Lead Diameter	0.6mm
Leakage Current	4 μ A
Lifetime	1000h
Terminal Type	Through Hole
Tolerance Plus	+20%