

規格 MICROPHONE SPECIFICATIONS

項目

1. ITEM: BLACK GENERAL PURPOSE MICROPHONE

型號

2. PART NO.: 3522698

電氣規格

3. ELECTRONICAL SPECIFICATIONS:

3.1 Directional Characteristics : Uni-Directional

3.2 Frequency : 70 Hz ~ 14,000 Hz

3.3 Impedance : $500\Omega \pm 30\%$ (at 1,000 Hz)

3.4 Sensitivity : $-75 \text{ dB} \pm 3 \text{ dB}$ (0 dB = 1 v/micro bar)
1,000 Hz indicated by open circuit)

機械規格

4. MECHANICAL SPECIFICATIONS:

4.1 Dimension : $\phi 54 \times 208 \text{ mm}$

4.2 Cable : $\phi 4 \pm 0.3 \text{ mm} / 3.0^{-0.0} \text{ M}$

4.3 Cable Plug : $\phi 6.3 \text{ mm}$, Mono, Nickel-Plated Pin

4.4 Weight : 183.5g (including cable)

測試規範

5. METHOD OF MEASUREMENT:

According to JIS C-5502


測試儀器

6. TEST INSTRUMENT :

Brüel & Kjær - Type 2012 with digital turntable system

曲線圖

7. FREQUENCY RESPONSE CURVE:

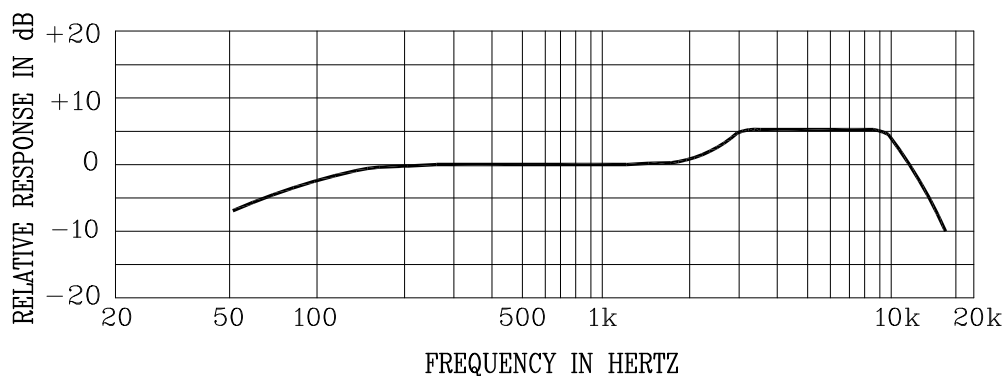

ELECTRET SPEC. CHECKED BY :

MECHANICAL SPEC. CHECKED BY :

PREPARED BY :