

規格 MICROPHONE SPECIFICATIONS

項目

1. ITEM : SURFACE MOUNT MICROPHONE

型號

2. PART NO. : 3522755

電氣規格

3. ELECTRONICAL SPECIFICATIONS:

3.1 Directional Characteristics : Omni-directional

3.2 Element : Back Electret-Condenser

3.3 Frequency : 50 Hz ~ 16,000 Hz

3.4 Impedance : $250\Omega \pm 30\%$ (at 1,000 Hz)

3.5 Sensitivity : $-59\text{ dB} \pm 3\text{ dB}$ (0 dB = 1 v/micro bar
1,000 Hz indicated by open circuit)

3.6 Switch : Slide Type

3.7 Operating Voltage : Battery, D.C. 1.5V, LR44

機械規格

4. MECHANICAL SPECIFICATIONS:

4.1 Dimensions : 57L x 57W x 14.5H mm

4.2 Cable Length and Plug :

Cable : $\phi 2.0 \times 3.0^{-0.0}$ M PVC Cable,

Plug : $\phi 3.5$, Gold-Plated Pin, 90°,
Mono Plug

4.3 Weight : 45 g (without battery)

測試規範

5. METHOD OF MEASUREMENT:

According to JIS C-5502


測試儀器

6. TEST INSTRUMENT :

Brüel & Kjær - Type 2012 with digital turntable system

曲線圖

7. FREQUENCY RESPONSE CURVE:

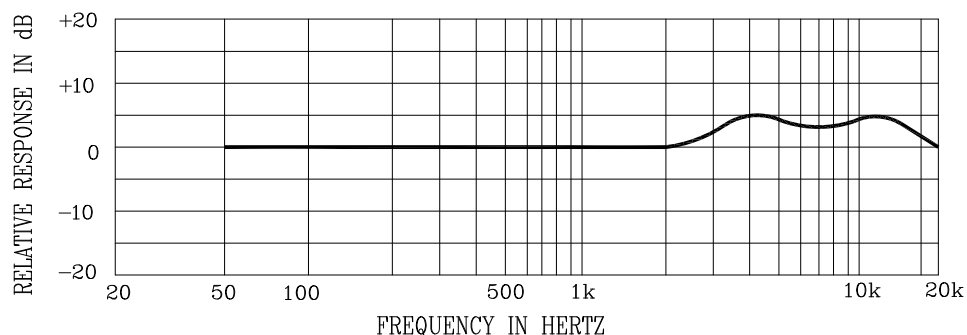

ELECTRET SPEC. CHECKED BY :

MECHANICAL SPEC. CHECKED BY :

PREPARED BY :