

規格

# MICROPHONE SPECIFICATIONS

項目:

1. ITEM: DESKTOP MICROPHONE

型號:

2. PART NO.: 3603977

電氣規格:

3. ELECTRICAL SPECIFICATIONS:

3.1 Directional Characteristics : Uni-directional (Cardioid)

3.2 Element : Back Electret Condenser

3.3 Frequency : 80 Hz ~ 14,000 Hz

3.4 Impedance :  $250 \Omega \pm 30\%$  (at 1,000 Hz)

3.5 Sensitivity :  $-60 \text{ dB} \pm 3 \text{ dB}$  (0 dB = 1 V/microbar,  
1,000 Hz indicated by open circuit)

3.6 Operating Voltage : Phantom Power; 22V~52V D.C.

3.7 Switch : Push Button (Lock Type)

機械規格:

4. MECHANICAL SPECIFICATIONS:

4.1 Dimensions :  $\varnothing 8\text{mm}$  (mic head) x 332mm (total length)

4.2 Connector : 3-Pins XLR(male)

測試規模:

5. METHOD OF MEASUREMENT:

According to JIS C-5502


測試儀器:

6. TEST INSTRUMENT :

Brüel & Kjær - Type 2012 with digital turntable system

曲線圖:

7. FREQUENCY RESPONSE CURVE:

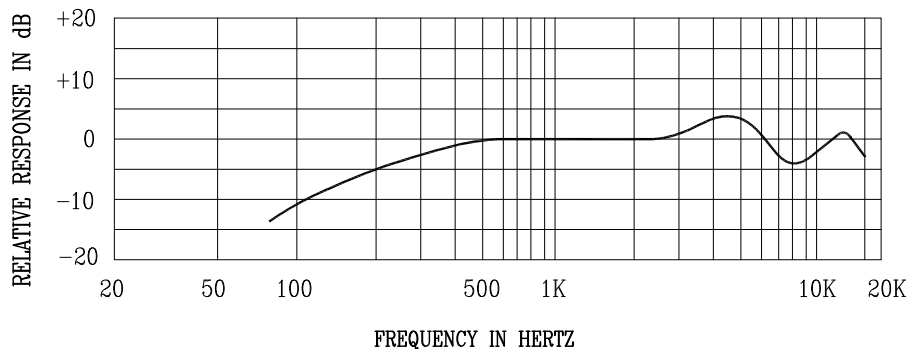

ELECTRET SPEC. CHECKED BY :	MECHANICAL SPEC. CHECKED BY :	PREPARED BY :
-----------------------------	-------------------------------	---------------