


# Data sheet

## PS

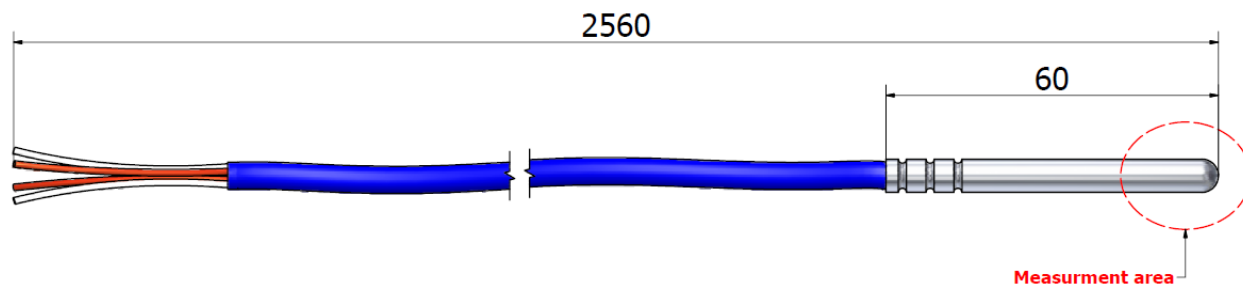

### PT100 THERMIC ELEMENT WITH CABLE AND TIP Ø 6

**RANGE :**

- 20°C / +200°C

**USE :**

- Universal, long time dumping

**KEY POINT :**

- Flexible

**SPECIFICATIONS :**

- PT100Ω thermic element A Class – 1x4 wires
- Tip in SS316L
- Cable 4 conductors, section 0.22mm  
Isolated Silicon/Copper braid/Silicon
- Leak tightness by 3 ring finger crimping

**DIMENSIONS:**

- Tip length = 60mm
- Tip diameter = 6mm
- Total length (tip + cable) = 2560mm

**METROLOGICAL DATA :**

- As per IEC 751
- Standard tolerance PT100 A class : ±0.15 + 0.002.[t°C]

**Other type:**

	<b>Length</b>	<b>2560mm</b>
<b>Wiring</b>		
Mounting 1x3wires		457-3704
<b>Mounting 1x4wires</b>		<b>407-1387</b>