

規格: MICROPHONE SPECIFICATIONS

項目:

1. ITEM : LAVALIER MICROPHONE

型號:

2. PART NO. : 2428911

電氣規格:

3. ELECTRICAL SPECIFICATIONS:

3.1 Directional Characteristics : Omni-directional

3.2 Element : Back Electret-Condenser

3.3 Frequency : 30 Hz ~ 18,000 Hz

3.4 Impedance : $1000\Omega \pm 30\%$ (at 1,000 Hz)

3.5 Sensitivity : $-65\text{ dB} \pm 3\text{ dB}$ (0 dB = 1 v/micro bar
1,000 Hz indicated by open circuit)

3.6 Operating Voltage : Battery, D.C. 1.5V, LR44

機械規格:

4. MECHANICAL SPECIFICATIONS:

4.1 Dimensions : $\phi 8 \times 16\text{ mm}$

4.2 Cable Length and Plug

Mic Unit to Control Box : $\phi 1.93 \times 1.0^{-0.0}\text{ M PVC Cable}$,

Output Side : $\phi 1.93 \times 5.0^{-0.0}\text{ M PVC Cable}$,

: $\phi 3.5$, Gold-Plated Pin, 90°, Mono Plug

4.3 Weight : 65 g

測試規範:

5. METHOD OF MEASUREMENT:

According to JIS C-5502


測試儀器:

6. TEST INSTRUMENT :

Brüel & Kjær - Type 2012 with digital turntable system

曲線圖:

7. FREQUENCY RESPONSE CURVE:

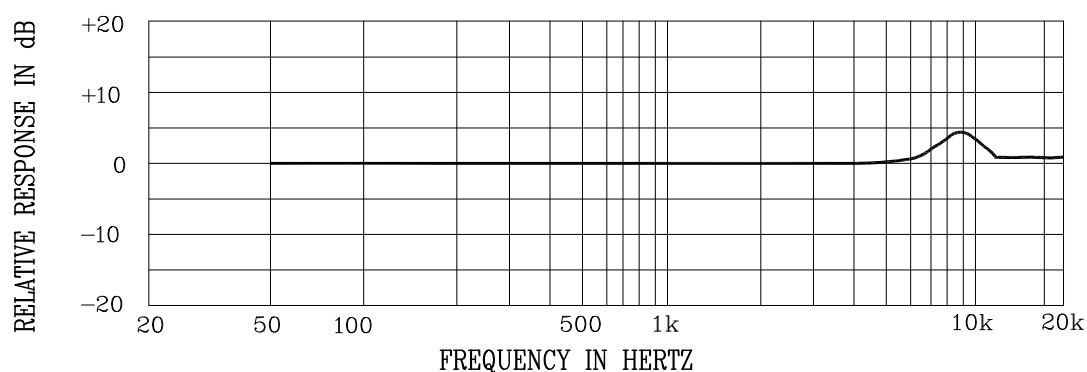

ELECTRET SPEC. CHECKED BY :

MECHANICAL SPEC. CHECKED BY :

PREPARED BY :