

Professionally approved products.

Datasheet

HSS Screwed Shank Counterbores



Description:

Right hand cutting counterbores designed to produce recessed holes for cap headed screws. Threaded shank.

Cutter Dimension D Tolerance = +0.013mm -0.05mm.

Dimension T Tolerance = e8.

Used to produce recessed holes for cap head screws.

Made to DIN 373 standards.

Material: High Speed Steel (HSS)

RS Code	Screw size	D mm	H mm	L mm	M mm	N mm	P mm	T mm
5227424	M4	8	5.5	65	28	6	12.5	4.3
5227430	M5	10	6.5	70	33	6	12.5	5.3
5227446	M6	11	8.0	76	39	6	12.5	6.4
5227452	M8	15	9.5	87.3	49	10	19.0	8.4
5227474	M10	18	11.0	89	51	10	19.0	10.5
5227480	M12	20	13.5	108	70	12	25.5	13.0

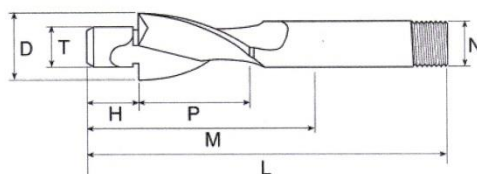


Figure 1