

Datasheet

# RS Pro 25 Way D Plug

RS Stock No: 382-2796



## Specifications:

### Materials

Unshielded Hood: UL-recognised plastic material

Operating Temperature:  $-30^{\circ}\text{C}$  to  $+110^{\circ}\text{C}$


Colour: Light Grey (Standard) Other colour on request

Shielded Hood: UL-recognised plastic material

Plating: Nickel over Copper

Operating Temperature:  $-30^{\circ}\text{C}$  to  $+90^{\circ}\text{C}$

Jackscrews: UNC 4-40 (Standard)

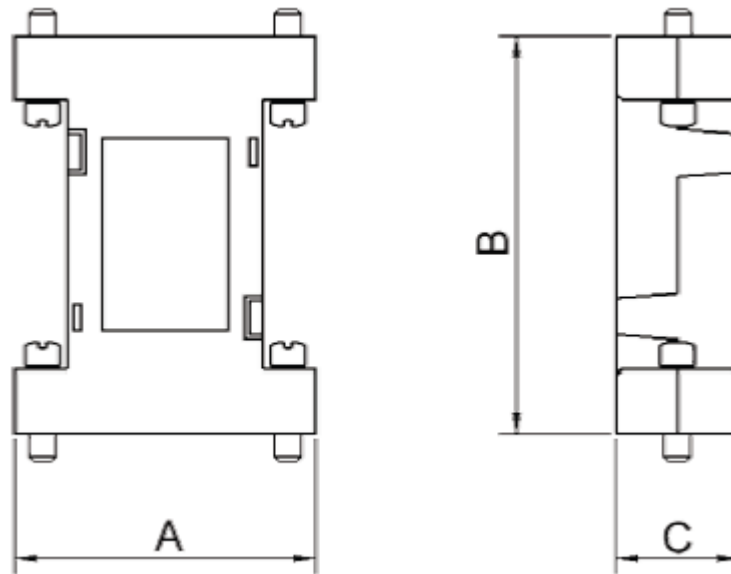

Size MHGA	Dim A	Dim B	Dim C
9-way	33,2	62,0	16,5
15-way	41,0	62,0	16,5
25-way	56,0	62,0	16,5

MM = Male to Male Sub-D

MF = Male to Female Sub-D

FF = Female to Female Sub-D