

Professionally approved products. Datasheet

Black 30m Antistatic PVC Air Hose, -15 → +60°C, Application Suitable for Food Use


RS Stock number 399-1173

Special Features

- Abrasion resistance - excellent
- Made from Cadmium free materials
- Resistance to a wide range of chemicals (see Chemical Resistance Table)
- Good flexibility
- High resistance to acids / alkalis
- Silicone free
- Service temperature -15°C to +60°C
- Low Toxic Linen - suitable for food use
- Anti Static
- Excellent transparency
- Manufactured to comply with BS6066 & ISO 5774
- All finished coils shrink wrapped



The connection device must be earthed/grounded.

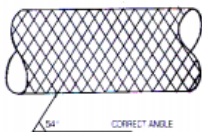

TECHNICAL DATA

EXTRA FLEXIBLE ANTI-STATIC AIR HOSE

(U.K. And European Sizes)

Product Ref.	Size (mm)		Roll Length in metres	Working Pressure @ + 20°C Factor 4:1 (BAR)
	I.D.	O.D.		
ESD06	6	11	30	10
ESD08	8	12	30	9
ESD10	10	14	30	8
ESD12	13	18	30	7

UK Standard Stock Sizes in 30m coils.

Conforms to product standards.

Test Methods & Procedures

SP - Method. 2472 section 7, rev 1 and section 7.3, rev 1

ESD Approved

BS 2050 : 1978 (1998) 4.12

BS EN ISO 7751 : 1997

ISO 1402 : 1994

BS EN 28033 : 1993

BS EN 24671 : 1993

ISO 8033 : 1991

BS EN 21746 : 1993