


Data sheet

PS

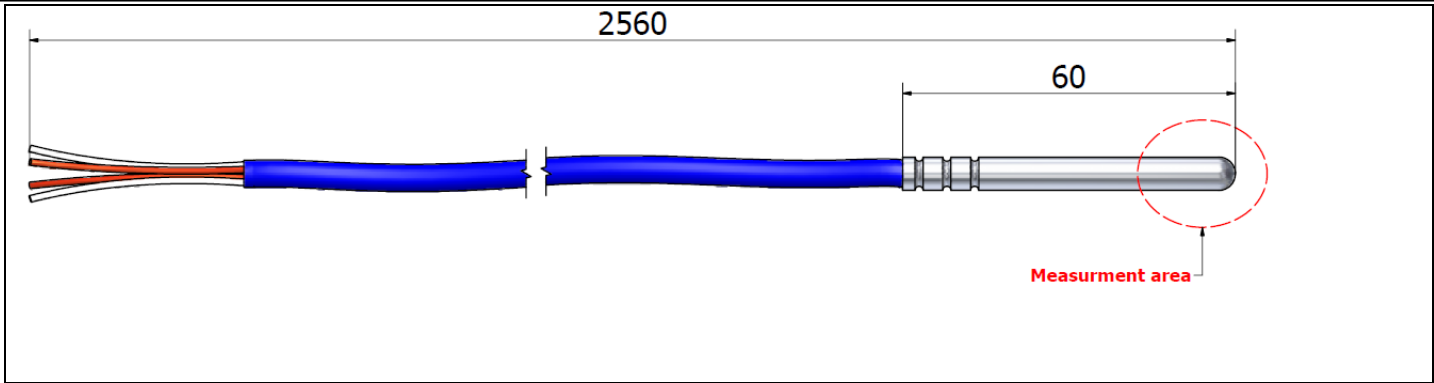

PT100 THERMIC ELEMENT WITH CABLE AND TIP Ø 6

RANGE :

- -20°C / +200°C

USE :

- Universal, long time dumping

KEY POINT :

- Flexible

SPECIFICATIONS :

- PT100Ω thermic element A Class – 1x3 wires
- Tip in SS316L
- Cable 3 conductors, section 0.22mm²
Isolated Silicon/Copper braid/Silicon
- Leak tightness by 3 ring finger crimping

DIMENSIONS :

- Tip length = 60mm
- Tip diameter = 6mm
- Total length (tip + cable) = 2560mm

METROLOGICAL DATA :

- As per IEC 751
- Standard tolerance PT100 A class : ±0.15 + 0.002.[t°C]

Other type:

Length	2560mm
Wiring	
Mounting 1x3wires	457-3704
Mounting 1x4wires	407-1387

