

RS P/N		A	B	C	COLOUR
467-2435-0001	CS265-PD1325SA1/4W7	12.7	25.4	13.0	SILVER
467-2429-0001	CS265-PD1325SB1/4W7	12.7	25.4	13.0	BLACK
467-2463-0001	CS265-PD1925SA1/4W7	19.0	25.4	13.0	SILVER
467-2441-0001	CS265-PD1925SB1/4W7	19.0	25.4	13.0	BLACK
467-2479-0001	CS265-PD1627SA6DW7	16.0	26.7	16.3	SILVER
467-2485-0001	CS265-PD1627SB6DW7	16.0	26.7	16.3	BLACK
467-2491-0001	CS265-PD2227SA6DW7	22.0	26.7	16.3	SILVER
467-2508-0001	CS265-PD2227SB6DW7	22.0	26.7	16.3	BLACK
467-2520-0001	CS265-PD3227SA6DW7	31.8	26.7	16.3	SILVER
467-2536-0001	CS265-PD3227SB6DW7	31.8	26.7	16.3	BLACK



CS265-PD1325SA



CS265-PD1627SA




CS265-PD1925SB



CS265-PD2227AS



CS265-PD3227SA

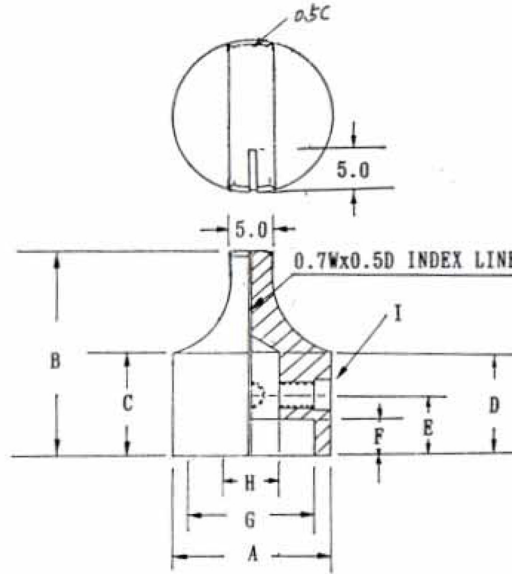

Material: Aluminum
Tolerance: +/-0.20
Unit : mm

P/N:		
	CS265-PD TYPE	
		Date: 6-Dec-13