


RS Stock No.517-3507
 RS Stock No.517-4409
 RS Stock No.517-3462
 RS Stock No.517-3484
 RS Stock No.517-3478
 RS Stock No.517-3434
 RS Stock No.517-4459
 RS Stock No.517-4465
 RS Stock No.517-3440
 RS Stock No.517-3456
 RS Stock No.517-3490
 RS Stock No.517-3529
 RS Stock No.517-3428
 RS Stock No.517-4421
 RS Stock No.517-3513

IP66 high temperature boxes (with seal ,no coating)

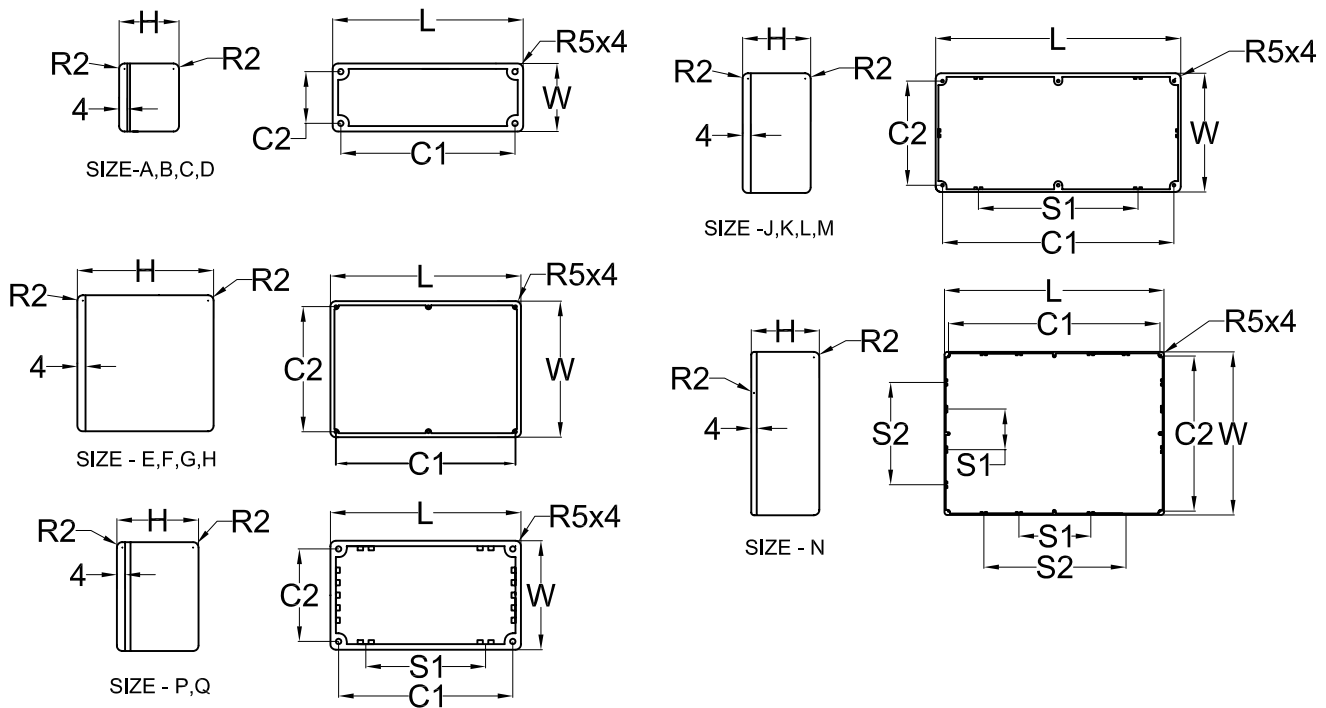

RS Stock NO.	Size NO.	L	W	H	C1	C2	S1	S2	Wall Thickness
5173507	A	89.1	35.0	31.3	79.3	25.3			1.5mm
5174409	B	114.5	63.6	31.3	104.5	54.2			1.5mm
5173462	C	114.7	89.7	56.1	104.4	79.6			1.5mm
5173484	D	114.4	63.7	56.1	104.6	54.2			2mm
5173478	E	172.0	120.9	56.0	160.4	109.3			2mm
5173434	F	172.1	120.9	107.0	160.4	109.3			2mm
5174459	G	222.1	145.9	56.9	211.7	135.4			2mm
5174465	H	222.2	146.0	107.5	211.7	135.4			2mm
5173440	J	275.0	175.0	66.5	264.1	164.0	132.2		2mm
5173456	K	139.1	101.5	77.7	128.7	90.7	64.8		2mm
5173490	L	165.8	127.3	77.3	154.0	116.1	77.1		2mm
5173529	M	119.9	100.0	36.7	108.5	88.4	50.1		2mm
5173428	N	250.2	250.2	101.5	238.0	238.0	79.9	160.0	2.5mm
5174421	P	79.9	54.9	26.1	70.5	45.4	40.0		1.5mm
5173513	Q	60.0	54.9	31.0	50.6	45.4	30.0		1.5mm

1. Material of the base and lid :Aluminium alloy ADC12
2. Material of the screws : Stainless M3.5x12mm Supadrive countersunk head
3. Finish:Natural plain
4. Seal :3mm thick balck self-adhesive synthetic rubber , Neoprene providing protection to IP66
5. Taper 1.5° Per side lid to base

