




RS Stock No.517-4263
 RS Stock No.517-4279
 RS Stock No.517-4285
 RS Stock No.517-4314

IP65 Coated Black Aluminum boxes (with seal ,coated black)

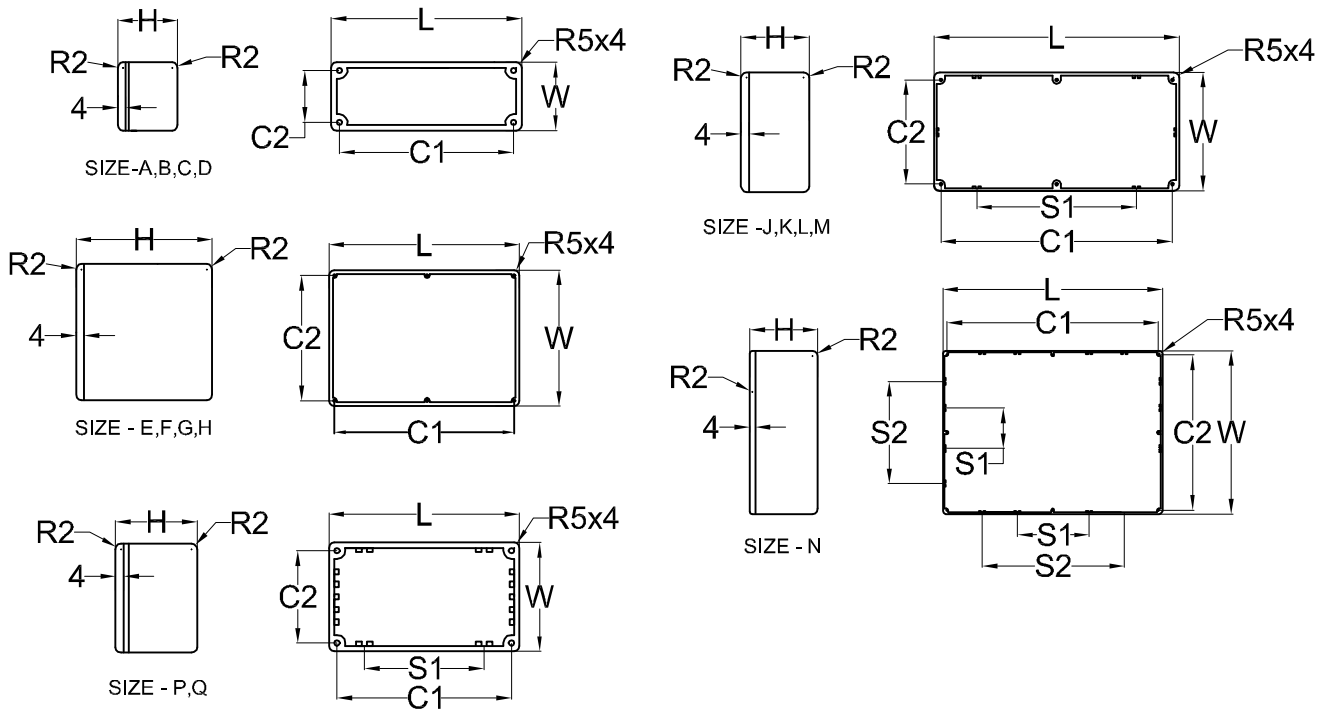

RS Stock NO.	Size NO.	L	W	H	C1	C2	S1	S2	Wall Thickness
	A	89.5	35.4	31.3	79.3	25.3			1.5mm
5174263	B	114.9	64.0	31.3	104.5	54.2			1.5mm
5174279	C	115.1	90.1	56.1	104.4	79.6			1.5mm
5174285	E	172.4	121.3	56.4	160.4	109.3			2.0mm
	L	166.2	127.7	77.7	154.0	116.1	77.1		2.0mm
5174314	N	250.6	250.6	101.9	238.0	238.0	79.9	160.0	2.5mm

1. Material of the base and lid :Aluminium alloy ,ADC12
2. Material of the screws: Stainless M3.5x12mm Supadrive countersunk head
3. Seal:3mm thick balck self-adhesive synthetic rubber , Neoperene providing protection to IP65
4. Finish:Powder coating
 - 4-1. Thickness:75~150 Micron inch (1.9um~3.8um)
 - 4-2. Color:Black RAL 9011
 - 4-3. Temperature resistance:
 - a. Max continuous working temp. 120 deg C.
 - b. Max short peak working temp. 150 deg C.
 - c. Melting temp. 180 deg C.
5. Taper 1.5° Per side to base

