


Data sheet

STRAIGHT MINI-UHF JACK – BNC PLUG ADAPTER

RS stock No: 5462560

NO	DESCRIPTION	DATE
△	REDUCE SPRING FROM 2 PCS TO 1 PC	07.07.97'
△	BACKGROUND FORMAT UPDATED	01.24.05'
△	BACKGROUND FORMAT UPDATED	02.04.09'
△	-55° C TO +85° C → -20°C TO+80° C	06.29.10'
△	WORKING VOLTAGE → VOLTAGE RATING DEL PROOF VOLTAGE J ADD VSWR	10.09.13'

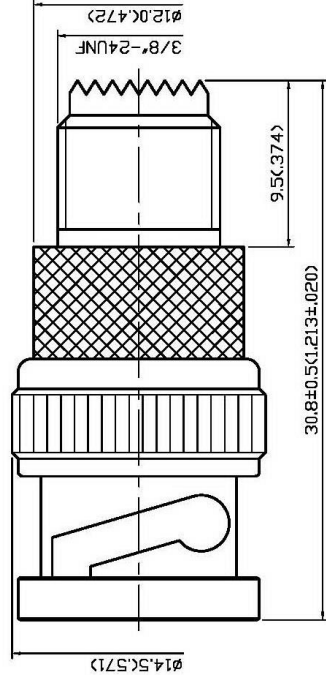

- 1.0 ELECTRICAL
 - 1.1 FREQUENCY RANGE: DC-2.5 GHz △
 - 1.2 NOMINAL IMPEDANCE: 50 OHMS △
 - 1.3 VOLTAGE RATING: 335 VOLTS MAX. △
 - 1.4 VSWR: 1.5 MAX. @2 GHz △
- 2.0 MATERIALS
 - 2.1 BODIES: BRASS PER JIS-C3604
 - 2.2 CENTER CONTACT: BRASS PER JIS-C3604
- 3.0 FINISHES AND OTHERS
- 3.1 SEE BELOW TABLE FOR DETAILS.
- 4.0 ENVIRONMENTAL
 - 4.1 OPERATING TEMPERATURE RANGE: -20°C TO+80° C / △

NO	DESCRIPTION	MATERIAL	Q'TY	FINISH
9	GASKET	RUBBER	1	RED
8	INSULATION II	POM	1	NONE
7	CENTER CONTACT	BRASS	1	GOLD
6	INSULATION I	POM	1	NONE
5	SPRING WASHER	SK-5	1	NICKEL
4	WASHER II	BRASS	1	NICKEL
3	WASHER I	BRASS	1	NICKEL
2	SHELL	BRASS	1	NICKEL 100μ" MIN.
1	BODY	ZINC	1	NICKEL

APPROVED by _____ DATE: _____

DESCRIPTION	TOLERANCE	品名	12-17	D.G.Z	DATE	版	REV.
STRAIGHT MINI-UHF JACK-BNC PLUG ADAPTER	±0.2	TITLE	ROHS COMPLIANT	(500)	1013.92'	次	A-5
製圖	X	單	UNIT	DWG.NO.	12-0046		
檢圖	.XX	位	mm(in)				
承認	.XXX	比	SCALE				
定	Jenny	例	SCALE				
	ANGLE ±5°	例	4:1				

