




# Data sheet THERMOCOUPLE

ENGLISH

RS Stock No. 621-2158

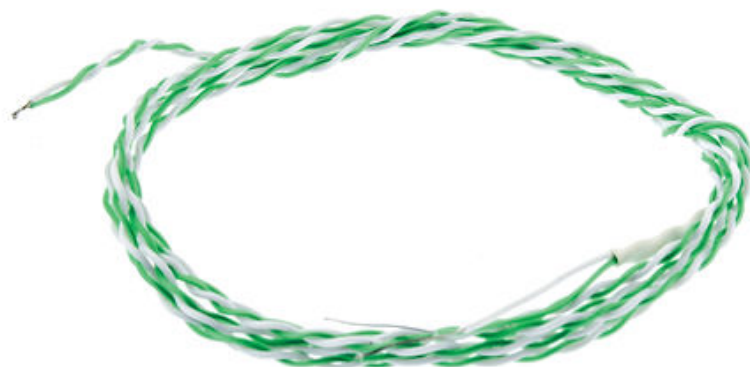

TYPE K THERMOCOUPLE RS																			
<b>RANGE :</b> <ul style="list-style-type: none"><li>50 / 250°C</li></ul>																			
<b>USE :</b> <ul style="list-style-type: none"><li></li></ul>																			
<b>KEY POINT :</b> <ul style="list-style-type: none"><li></li></ul>																			
<b>SPECIFICATIONS :</b> <ul style="list-style-type: none"><li>Matter = PTFE</li><li>Hot junction grouded</li></ul>																			
<b>DIMENSIONS :</b> <ul style="list-style-type: none"><li>Cable length = 1000 mm</li></ul>																			
<b>METROLOGICAL DATA :</b> <ul style="list-style-type: none"><li>As per IEC 584</li><li>Standard tolerance TC "K" class1: -40°C &lt; t° &lt; 375°C = ± 1.5°C 375°C &lt; t° &lt; 1000°C = ± 0.004. [t]</li><li>Time constant at 63% in water: 0.7 sec</li><li>Output signal FEM(mV) as per curve of "K" type as per norme IEC 60584</li></ul>																			
<b>Other type:</b>																			
<table border="1"><thead><tr><th>tolerence</th><th>J</th><th>K</th><th>N</th><th>T</th></tr></thead><tbody><tr><td>Length</td><td></td><td></td><td></td><td></td></tr><tr><td>1000</td><td>621-2142</td><td>621-2158</td><td>621-2136</td><td>621-2164</td></tr></tbody></table>					tolerence	J	K	N	T	Length					1000	621-2142	621-2158	621-2136	621-2164
tolerence	J	K	N	T															
Length																			
1000	621-2142	621-2158	621-2136	621-2164															