

# PLASTIC UTILITY ENCLOSURE



- Moulded in high impact abs which is flame retardant to both UL94-V0 and UL94-HB.
- Available in White(RAL9002, UL94-V0 of ABS) or Black(RAL9005, UL94-HB of ABS).
- Ideally design for portable , desktop or wall mounted electronic application.
- Space of the recessed area are designed for 4.3" , 5.7" , 7.0" , 8.4" & 10.4" lcd module or touch screen use.
- Lid & base incorporate a tongue and groove sealing design, optional EPDM gasket can be ordered and installed to meet IP65 rating of waterproof and dust.
- Recommended working temperature : -20°C to 80°C.
- Put-on rubber feet are included.




White



Black


**MATERIAL: UL94-V0 of ABS**

STOCK NO.	Color	EXTERNAL DIMENSION (mm)		
		LENGTH	WIDTH	HEIGHT
774-3732	White	140	100	30
774-3735	White	190	150	30
774-3739	White	221	161.5	30
774-3748	White	279	206	30
774-3741	White	322	232	30

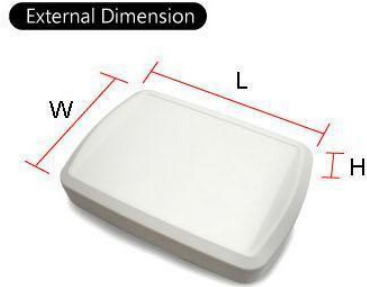

**MATERIAL: UL94-HB of ABS**

STOCK NO.	Color	EXTERNAL DIMENSION (mm)		
		LENGTH	WIDTH	HEIGHT
774-3745	Black	140	100	30
774-3754	Black	190	150	30
774-3757	Black	221	161.5	30
774-3751	Black	279	206	30
774-3760	Black	322	232	30

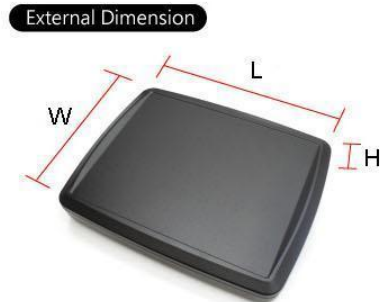

**Gasket**

**Product description**  
 Φ2.3mm EPDM Gasket.

**Example**



**Content**

