

Professionally approved products.

Datasheet


12 way PCB terminal block 5.08mm

RS Stock 790-1095



Dimensions: (mm)

PCB Layout

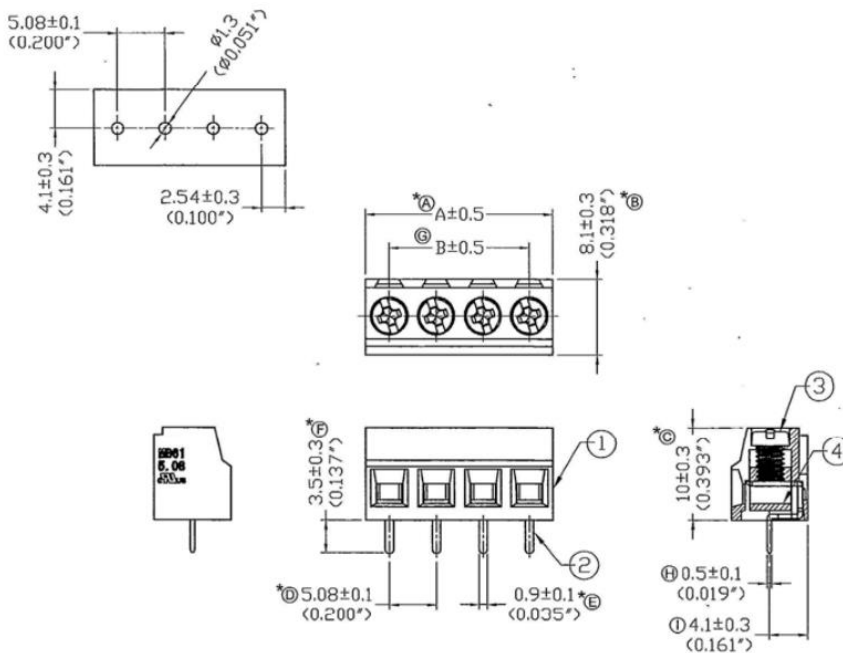

Specification

Current Rating: 16Amp AC300V
 Insulation Withstands Volts: AC2000V Min
 Insulation Resistance: >2000M Ω DC500V
 Operation Temperature: -40°C to + 105°C
 Wire Strip Length: 4mm~5mm
 Wire Range: 14~26AWG
 Screw Torque: 4.5lb-inch

Material

Insulating Body: Polyamide 66(UL94V-0)
 Slide Cover: Polyamide 66(UL94V-0)
 Contact Pin: Phosphor Bronze / Finish: Tin Plated
 Colour: Green