




**Professionally approved products.**


Product Datasheet

## **Single Universal Joint with Plain Bearing**

EN

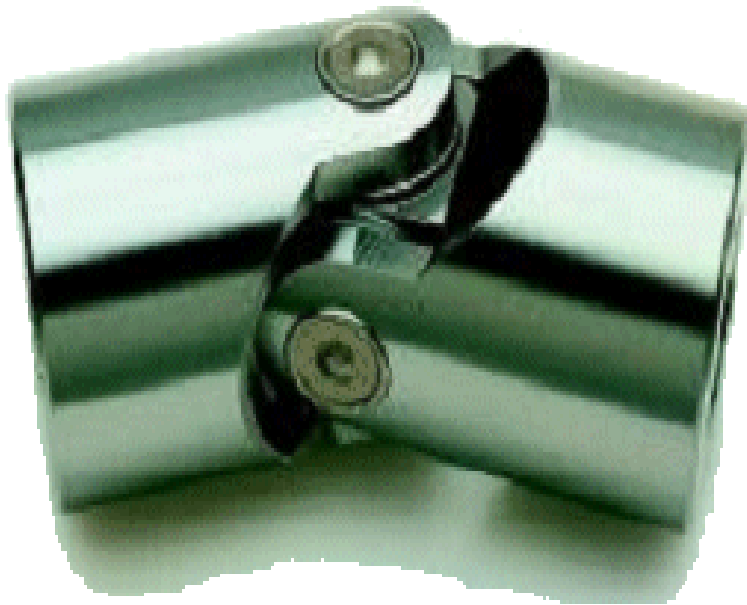

UJSP Properties	
Maximum working angle	45 degrees
Maximum speed	1000 rpm
Maximum power	6 kW
Maximum torque	600 Nm

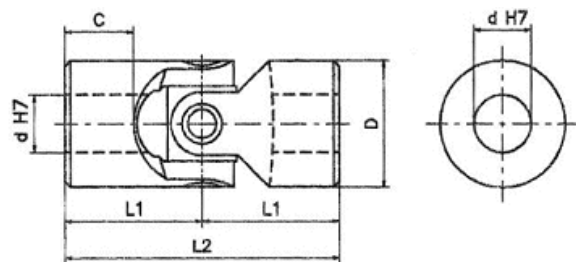

**Dimensions in mm**

RS Stock No	Manufacturers part No.	Bore d	Diameter	Overall length	Pivot centre	Hub length	Weight	Gaiter RS Stock No
		H7	D	L2	L1	C	KG	
7906699	UJSP16X6	6	16	34	17	8	0.05	7906832
7906693	UJSP16X8	8	16	40	20	11	0.05	7906832
7906703	UJSP22X10	10	22	48	24	12	0.1	7906839
7906706	UJSP25X12	12	25	56	28	13	0.1	7906848
7906700	UJSP28X14	14	28	60	30	14	0.2	7906841
7906719	UJSP32X16	16	32	68	34	16	0.3	7906845
7906712	UJSP36X18	18	36	74	37	17	0.45	7906854
7906716	UJSP42X20	20	42	82	41	18	0.6	7906857
7906725	UJSP45X22	22	45	95	47.5	22	0.95	7906851
7906728	UJSP50X25	25	50	108	54	26	1.2	7906860

NB : It is recommended that all plain bearings be used with a protective gaiter to assist lubrication and arrest the ingres of dirt.