



**Professionally approved products.**

Product Datasheet


## **Long Single Universal Joint with Plain Bearing**

EN





UJSPL Properties	
Maximum working angle	45 degrees
Maximum speed	1000 rpm
Maximum power	6 kW
Maximum torque	600 Nm

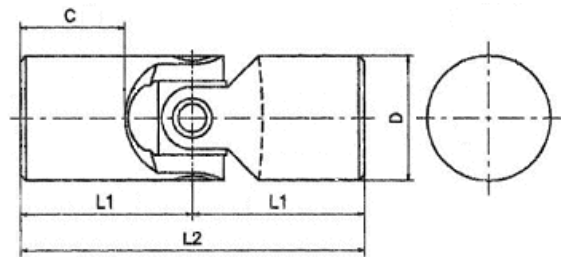

### Dimensions in mm

RS Stock No	Manufacturers part No.	Bore d H7	Diameter D	Overall length L2	Pivot centre L1	Hub length C	Weight KG	Gaiter RS stock No
7906722	UJSPL16X10	10	16	56	28	19	-	7906832
7906731	UJSPL22X12	12	22	76	38	26	-	7906839
7906734	UJSPL25X16	16	25	86	43	28	-	7906848
7906738	UJSPL32X20	20	32	95	47.5	29.5	-	7906845
7906747	UJSPL42X25	25	42	127	63.5	40.5	-	7906857

NB : It is recommended that all plain bearings be used with a protective gaiter to assist lubrication and arrest the ingres of dirt.