



Professionally approved products.


Product Datasheet

Double Universal Joint with Plain Bearing

EN



UJDP Properties	
Maximum working angle	90 degrees
Maximum speed	1000 rpm
Maximum power	6 kW
Maximum torque	600 Nm

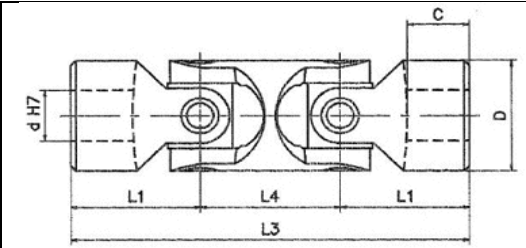

Dimensions in mm

RS Stock No	Mfr part No.	Bore d H7	Dia. D	Overall length L3	Pivot to face centre L1	Pivot to pivot centre L4	Hub Length C	Weight KG	Gaiter RS Stock No
7906740	UJDP16X6	6	16	56	17	22	8	0.08	7906832
7906744	UJDP16X8	8	16	62	20	22	11	0.08	7906832
7906753	UJDP22X10	10	22	74	24	26	12	0.15	7906839
7906756	UJDP25X12	12	25	86	28	30	13	0.25	7906848
7906750	UJDP28X14	14	28	96	30	36	14	0.40	7906841
7906769	UJDP32X16	16	32	104	34	36	16	0.45	7906845
7906762	UJDP36X18	18	36	114	37	40	17	0.70	7906854
7906766	UJDP42X20	20	42	128	41	46	18	1.00	7906857
7906775	UJDP45X22	22	45	145	47.5	50	22	1.50	7906851
7906778	UJDP50X25	25	50	163	54	55	26	2.00	7906860

NB: It is recommended that all plain bearing joints should be used with a protective gaiter to assist lubrication and help arrest the ingress of dirt.