




Professionally approved products.


Product Datasheet

Single Universal Joint with Needle Roller Bearing

EN

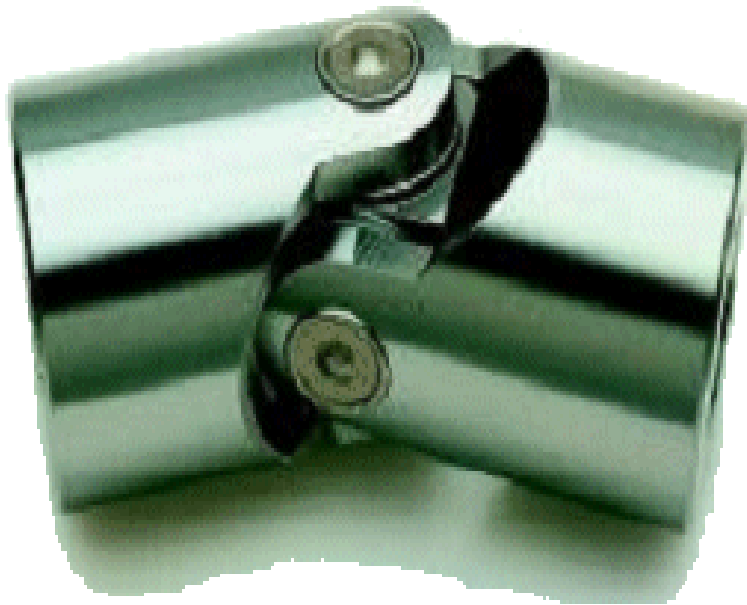

UJSN Properties	
Maximum working angle	45 degrees
Maximum speed	4000 rpm
Maximum power	40 kW
Maximum torque	200 Nm

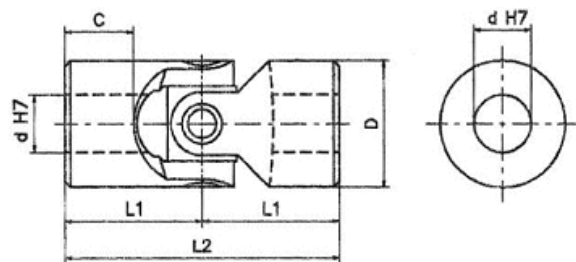

Dimensions in mm

RS Stock No	Manufacturers part No.	Bore d H7	Diameter D	Overall length L2	Pivot centre L1	Hub length C	Weight KG
7906772	UJSN22X10	10	22	48	24	12	0.1
7906781	UJSN25X12	12	25	56	28	13	0.16
7906784	UJSN28X14	14	28	60	30	14	0.2
7906788	UJSN32X16	16	32	68	34	16	0.3
7906797	UJSN36X18	18	36	74	37	17	0.45
7906790	UJSN42X20	20	42	82	41	18	0.6
7906794	UJSN45X22	22	45	95	47.5	22	0.95
7906804	UJSN50X25	25	50	108	54	26	1.2

NB: Protective gaiters are unnecessary for most applications.