

**Professionally approved products.**


## Datasheet

### RPSMA - UFL RF cable assembly

RS Stock number 794-2835



#### Dimensions: (mm)

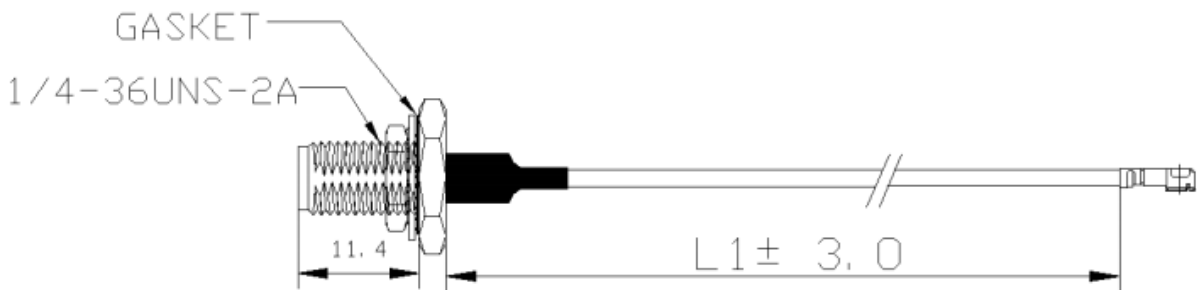

## Specification

#### PRODUCT MATERIAL

1. SMA IP67 B/H JACK CRIMP TYPE FOR  $\varnothing 1.37\text{mm}$  CABLE NUT x 1, WASHER x 1
2. U.FL-LP-088 Halogen Free For  $\varnothing 1.37\text{mm}$  Cable
3. U.FL-088 CONTACT For  $\varnothing 1.37\text{mm}$  Cable
4. 1.37mm CABLE TIN PLATED COLOR:BLACK
5. HEAT SHRINK TUBE F32  $\varnothing 2.5\text{mm}$  L=15.0mm COLOR:BLACK.

#### ELECTRICAL PERFORMANCE:

- 1.IMPEDANCE:50 OHMS
- 2.FREQUENCY RANGE:DC~3GHz
- 3.WORKING VOLTAGE:250Vrms MAXIMUM
- 4.DIELECTRIC WITHSTANDING VOLTAGE:750Vrms min.